


# Narrow spur rack



## Module 0.4-2.0


Steel

- Pressure angle 20°
- Max length from 400 to 1800 depending on module
- 1 metre lengths can be joined end to end
- Materials:
  - Module 0.4 to 0.7 mild steel
  - Module 0.8 to 2.0 steel 60C40 or C35/C45
- Max. pitch error up to module 0.7:  
1mm/300mm
- Max. pitch error from module 0.8:  
0.1mm/300mm

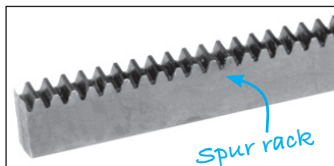

### Option

 - Other lengths available for quantities of 5 or more, please contact us



### DISCOUNTS

Qty	1+	3+	6+	10+
Disc.	List	-10%	-15%	On request

Part number	Module	P	W	H	L	Stock*	Price each 1 to 2
R0.4-400	0,4	11,60	6	12	400	✓	91,49 €
R0.5-400	0,5	11,50	6	12	400	✓	34,14 €
R0.8-1000	0,8	11,20	6	12	1000	✓	179,63 €
R1-1000	1	14,00	8	15	1000	✓	92,71 €
R1.25-1000	1,25	13,75	8	15	1000	✓	161,08 €
RR1.5-1000	1,5	16,50	18	18	1000	✓	147,23 €
RR2-1000	2	16,00	18	18	1000	✓	157,19 €

\*Depending on availability - Dimensions in mm

## Our other products



VTLM  
3 lobed handle,  
Polyamide - Steel



RAS  
90° ball and socket  
joints DIN71802,  
Stainless steel



T5M T10M  
T type timing belt per  
metre, T5 Steel cored  
polyurethane



LRRss  
Latch, Spring loaded  
latch - stainless steel



J51  
Spur gear coaxial  
gearbox, from 0.13 to  
0.49 Nm - Inline



BPHT  
Ball transfer unit bolt  
fitting, Heavy



M2  
Worm and wheel set,  
Machined plastic  
(delrin)



HS  
Hexagonal spacer,  
Stainless steel 303



GP  
Spring loaded toggle  
latch, Standard



BIMSS  
Indexing plunger mini,  
miniature - Stainless




DOG258  
Motor-gearbox 12V  
and 24V DC, from 12



LVT  
Miniature motorised  
actuator 1A, 1 amper

## Complementary products

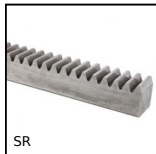

SR  
Narrow spur rack,  
Stainless steel