


Narrow spur rack



Module 0.4-2.0


Steel

- Pressure angle 20°
- Max length from 400 to 1800 depending on module
- 1 metre lengths can be joined end to end
- Materials:
 - Module 0.4 to 0.7 mild steel
 - Module 0.8 to 2.0 steel 60C40 or C35/C45
- Max. pitch error up to module 0.7:
1mm/300mm
- Max. pitch error from module 0.8:
0.1mm/300mm

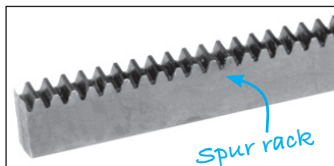

Option

 - Other lengths available for quantities of 5 or more, please contact us



DISCOUNTS

Qty	1+	3+	6+	10+
Disc.	List	-10%	-15%	On request

Part number	Module	P	W	H	L	Stock*	Price each 1 to 2
R0.4-400	0,4	11,60	6	12	400	✓	91,49 €
R0.5-400	0,5	11,50	6	12	400	✓	34,14 €
R0.8-1000	0,8	11,20	6	12	1000	✓	179,63 €
R1-1000	1	14,00	8	15	1000	✓	92,71 €
R1.25-1000	1,25	13,75	8	15	1000	✓	161,08 €
RR1.5-1000	1,5	16,50	18	18	1000	✓	147,23 €
RR2-1000	2	16,00	18	18	1000	✓	157,19 €

*Depending on availability - Dimensions in mm

Our other products




DOMI30

Domino 30 adjustable slide, Slide DOMILINE 30



DOMI120

 Accessories, Plate



M2

Worm and wheel set, Machined plastic (delrin)



GET-AL

Jaw coupling, economy range, Aluminium



PRF-SMA

Closing system for aluminium profile, Easily adjustable lock



DPAR_DKON

Progressive stop, Steel



ERC

Quick fitting cable terminal, Fork



MEF

Cylindrical sintered ferrous bush, Self-lubricating FP20 ferrous all...



 
BABtss

303 Stainless steel ball pin, 303 Stainless



ZBRA

Machined plastic bevel gear, 1:1



JFM

Flanged polymer bush, Universal



F7-E

Multifunction display, With external sensor

Complementary products



SR

Narrow spur rack, Stainless steel