



# Roller guide



For guiding products

RAG

- Length: 1000 mm
- Materials:  
Profile and bars: stainless steel  
Rollers: polyacetal

## Accessories

- Anchoring system RAG-M8

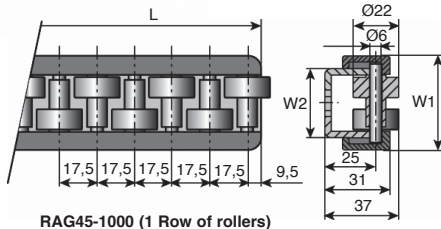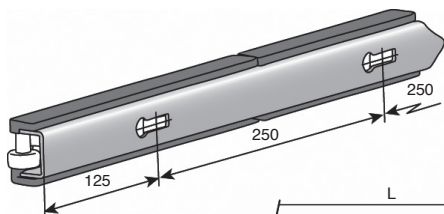

## DISCOUNTS

Qty	1+	2+	6+
Disc. List	-10%		On request

Part number	W1	W2	L (mm)	No. of rows	Weight (kg)	Stock*	Price each
RAG45-1000	45	33	1000	1	2,41	✓	145,72 €
RAG70-1000	70	58	1000	2	3,50	✓	168,98 €
RAG96-1000	96	84	1000	3	4,60	✓	217,54 €
RAG120-1000	120	108	1000	4	5,75	✓	285,10 €

\*Depending on availability - Dimensions in mm

Fax: 0 825 88 6000 Service 0,15 €/mln + prix appel

cial2@hpcurope.com

WEB  
04/2020

HPC

## Our other products



RIMple

Locking castor, with mounting plate



HW\_HT

Half-rail guide, Wheel



BCFH

Mushroom headed button Hygienic Usit®, With male thread and high head



ACLBTS

Spherical ended stop for aluminium profile, Spherical ended stop



RPC

Wheel, Polyamide



NSA

Adjustable clamp, Articulated



RFK48B

Hypoid gearbox - Stainless steel, up to 350 Nm



H1

Crossed helical gear crossed axis at 90°, Steel 20NCD2



TBV

Manual lifting tables, 7kg



AC

Strike for toggle latch, 15mm



M0

Worm and wheel set, Non hardened steel



DB

Steel bevel gear, 2:1

## Complementary products



RAG-12-M8

Roller guide accessory, Anchoring system



TOC

Short swivel head, Short



RAGFLOW

Floway2® roller track, Roller track