



Roller guide



For guiding products

RAG

- Length: 1000 mm
- Materials:
Profile and bars: stainless steel
Rollers: polyacetal

Accessories

- Anchoring system RAG-M8

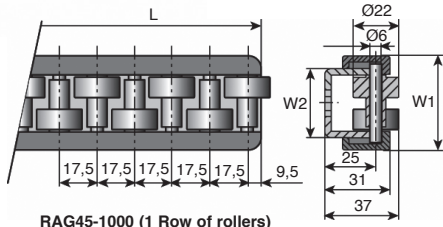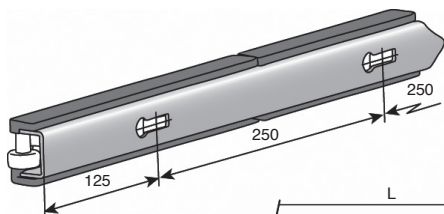

DISCOUNTS

Qty	1+	2+	6+
Disc. List	-10%		On request

Part number	W1	W2	L (mm)	No. of rows	Weight (kg)	Stock*	Price each
RAG45-1000	45	33	1000	1	2,41	✓	145,72 €
RAG70-1000	70	58	1000	2	3,50	✓	168,98 €
RAG96-1000	96	84	1000	3	4,60	✓	217,54 €
RAG120-1000	120	108	1000	4	5,75	✓	285,10 €

*Depending on availability - Dimensions in mm

 
Fax: 0 825 88 6000 Service 0,15 €/mln + prix appel

cial2@hpcurope.com

WEB
04/2020

HPC

Our other products



M2

Worm and wheel set,
Machined plastic
(delrin)



GARDLL

Mounting sleeve for
lock pin, Nickel-plated
steel or Stainless steel



SSHBRA

Stainless steel bevel
gear, 1,5:1 2:1 3:1



Q6

Deep groove ball
bearing, Steel



T10_21_AL

T type timing pulley,
Economy range - T10
aluminium



PR105

Articulated foot Ø103,
Ø 103



DER63

Stainless steel AC
asynchronous motor
0.18 kW, 0.18kW



STRIP

Sealing brush strip,
3m length



BLH40

Right angled gearbox,
from 3 to 10.30 Nm



PW_PWG2

Worm - precision
range, Steel



PRF-SCL

Lock for aluminium
profile, Lock for



KSTM

Igubal® pillow block
bearing, Polymer

Complementary products



RAG-12-M8

Roller guide
accessory, Anchoring
system



TOC

Short swivel head,
Short



RAGFLOW

Floway2® roller track,
Roller track