



Roller guide



For guiding products

RAG

- Length: 1000 mm
- Materials:
Profile and bars: stainless steel
Rollers: polyacetal

Accessories

- Anchoring system RAG-M8

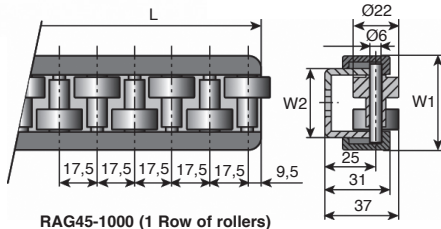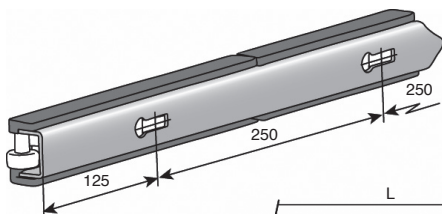

DISCOUNTS

Qty	1+	2+	6+
Disc. List	-10%		On request

Part number	W1	W2	L (mm)	No. of rows	Weight (kg)	Stock*	Price each
RAG45-1000	45	33	1000	1	2,41	✓	145,72 €
RAG70-1000	70	58	1000	2	3,50	✓	168,98 €
RAG96-1000	96	84	1000	3	4,60	✓	217,54 €
RAG120-1000	120	108	1000	4	5,75	✓	285,10 €

*Depending on availability - Dimensions in mm

Our other products



HTD5M_09

HTD Heavy duty timing pulley, HTD5 Steel



SHTP

Drylin® Linear table, Economy range



BLH20

Right angled gearbox, from 0.53 to 1.77



COA-COG

Surface mounting plate, Surface mounting plate for ball joint



H2

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



EPRC

High helix leadscrew, Cylindrical nut - up to 40mm per rotation



ACLPP

Latch for aluminium profile, Spring operated latch



SLV

Vertical toggle clamp, Vertical Lever Clamp - steel



BABFCFO

Ball pin socket, Mounting collar with a round flange



MRASSeco

Low cost stainless steel quick link, Stainless steel



BLHT70

Right angled gearbox, from 26 to 128 Nm



CHTRP

Single and dual output gearboxes, Up to 9,1 Nm

Complementary products



RAG-12-M8

Roller guide accessory, Anchoring system



TOC

Short swivel head, Short



RAGFLOW

Floway2® roller track, Roller track