



Roller guide



For guiding products

RAG

- Length: 1000 mm
- Materials:
Profile and bars: stainless steel
Rollers: polyacetal

Accessories

- Anchoring system RAG-M8

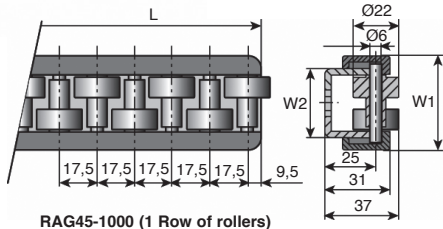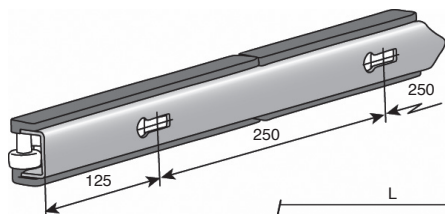

DISCOUNTS

Qty	1+	2+	6+
Disc. List	-10%		On request

Part number	W1	W2	L (mm)	No. of rows	Weight (kg)	Stock*	Price each
RAG45-1000	45	33	1000	1	2,41	✓	145,72 €
RAG70-1000	70	58	1000	2	3,50	✓	168,98 €
RAG96-1000	96	84	1000	3	4,60	✓	217,54 €
RAG120-1000	120	108	1000	4	5,75	✓	285,10 €

*Depending on availability - Dimensions in mm

Our other products



Telescopic drawer,



 
Screen support, Basic support



Sliding nut, For T slot



Swivel castor with double brake, Steel - grey rubber



Wear strip for slat top chain, L profile to be clipped



Square tube connector, Fixed angle



Internal gear, Steel 20NCD2



 
T type timing belt per metre, T5 Steel cored polyurethane



Speed controller 5A, 5 A



Shoulder screw ISO7379, Hardened Steel class 12.9



Spring loaded position switch, Electric contact



T type timing pulley, Economy range - T10 moulded plastic (nylon)

Complementary products



Roller guide accessory, Anchoring system



Short swivel head, Short



Floway2® roller track, Roller track