



Roller guide



For guiding products

RAG

- Length: 1000 mm
- Materials:
Profile and bars: stainless steel
Rollers: polyacetal

Accessories

- Anchoring system RAG-M8

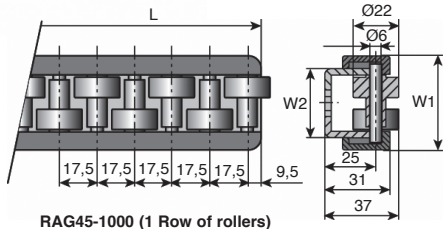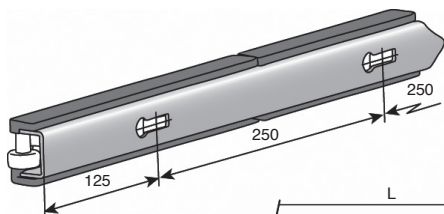

DISCOUNTS

Qty	1+	2+	6+
Disc. List	-10%		On request

Part number	W1	W2	L (mm)	No. of rows	Weight (kg)	Stock*	Price each
RAG45-1000	45	33	1000	1	2,41	✓	145,72 €
RAG70-1000	70	58	1000	2	3,50	✓	168,98 €
RAG96-1000	96	84	1000	3	4,60	✓	217,54 €
RAG120-1000	120	108	1000	4	5,75	✓	285,10 €

*Depending on availability - Dimensions in mm

Our other products



BLHT70
Right angled gearbox,
from 26 to 128 Nm



EML
Stainless steel
hexagonal headed
thumb nut, Lobed
handscrew



DOG258
Motor-gearbox 12V
and 24V DC, from 12
to 15 Nm



BL15
Right angled gearbox,
from 1.10 to 6 Nm



PGNT
Thermoplastic T
handle, With threaded
insert




SH1
Parallel axis helical
gear, Machined plastic
(delrin)




STU
Stroke rotary bushing,
Steel



 EHD16
Internal epicyclic
servo reducers, from
210 to 380 Nm



 PRZ
Wear strip for slat top
chain, Z profile to be
clipped



IN1
Internal gear,
Machined plastic
(delrin)



KB_OP
Open precision linear
bearing, Precision -
steel



PRES5HR
Manual workbench
press, Force up to
500kg

Complementary products



RAG-12-M8
Roller guide
accessory, Anchoring
system



TOC
Short swivel head,
Short