



- Mini roller conveyor prevents damage to parts
- Surface-friendly fibre arrangement
- Dirt adhesion is prevented
- Reduced manual effort
- Easy handling in all direction

Materials


- Plastic roller, polyamide fibres
- Steel rail

Advantages

- Ideal for sensitive products
- Quiet conveying

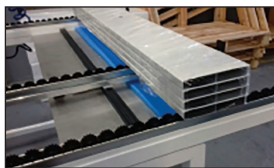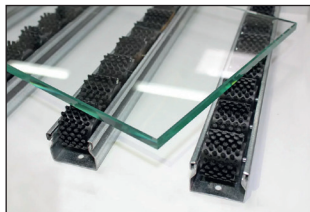

Typical application

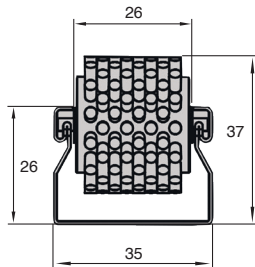

DISCOUNTS

Qty	1+	2+	5+	10+	20+
Disc. List	-5%	-11%	-14%	On request	

Part number	Length L (mm)	Space between rollers (mm)	Nb of rollers	Load-bearing capacity per 1 m track (kg)	Price each.
Low density					
RAG-B30-2000	2000	66	30	25	
High density					
RAG-B60-2000	2000	33	60	50	

Dimension in mm

Our other products



HLUT

Spoked handwheel
with handle,
Aluminium



CMM

Male rod ends DIN
ISO12240-4, Steel /
bronze



PLM-C

Flat gripping magnet,
Flat holding magnet



HK

Manual locking clamp,
Manual locking clamp
T



GE1006

Elastic ringed latch,
Hooks into a slot



BPFss

Pressed stainless steel
flange bearing,
Stainless steel



OP6

Mechanical digital
position indicator, 5
numbers



EHD12

Internal epicyclic
servo reducers, from
60 to 140 Nm



SCH

Horizontal hook
toggle clamp,
Horizontal Hook



KB_UU

Closed linear
precision bearing,
Precision - steel



TCXR

Automatic chain
tensioner, With steel
sprocket



SVR30

Screwjack with
travelling nut, with
moving nut

Complementary products



RAGFLOW

Floway2® roller track,
Roller track



RAGFLOWsupport

Floway2® Roller track
accessory, Roller
track support



RAG

Roller guide,