



- Mini roller conveyor prevents damage to parts
- Surface-friendly fibre arrangement
- Dirt adhesion is prevented
- Reduced manual effort
- Easy handling in all direction

Materials


- Plastic roller, polyamide fibres
- Steel rail

Advantages

- Ideal for sensitive products
- Quiet conveying

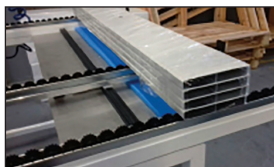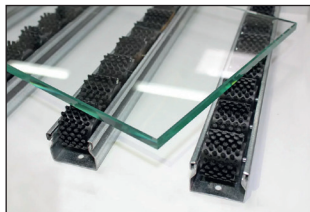

Typical application

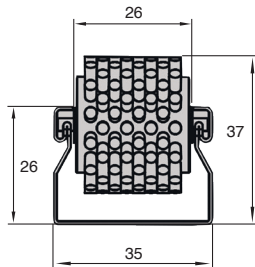

DISCOUNTS

| | | | | | |
|-------|------|-----|------|------|------------|
| Qty | 1+ | 2+ | 5+ | 10+ | 20+ |
| Disc. | List | -5% | -11% | -14% | On request |


| Part number | Length L (mm) | Space between rollers (mm) | Nb of rollers | Load-bearing capacity per 1 m track (kg) | Price each. |
|---------------------|---------------|----------------------------|---------------|--|-------------|
| Low density | | | | | |
| RAG-B30-2000 | 2000 | 66 | 30 | 25 | |
| High density | | | | | |
| RAG-B60-2000 | 2000 | 33 | 60 | 50 | |

Dimension in mm

Our other products



 BPFss
Pressed stainless steel flange bearing,
Stainless steel



RPP8
RPP heavy duty timing belt, RPP8



BTC20_10
End cap for rectangular tube,
Standard



PSG3
Spur gear - precision range, Pre-hardened
Steel 35NCD6



GBS
Nut for ballscrew,
Flanged ballscrew nut



 
PTMC
Telescopic furniture
foot, square plate



AKN
Bellows coupling
Gerwah®, from 22 to
180Nm



CHA_GC_9SS
Stainless steel garnet
hinge, To be welded



LFM
Steel leadscrew,
Medium carbon steel -
1 thread



TS01_TW01
Drylin® T linear slide,
up to 7000 N



ZDB
Machined plastic
bevel gear , 2:1



H2
Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)

Complementary products