

For gentle conveying and handling

RAGB



- Mini roller conveyor prevents damage to parts
- Surface-friendly fibre arrangement
- Dirt adhesion is prevented
- Reduced manual effort
- Easy handling in all direction

Materials


- Plastic roller, polyamide fibres
- Steel rail

Advantages

- Ideal for sensitive products
- Quiet conveying

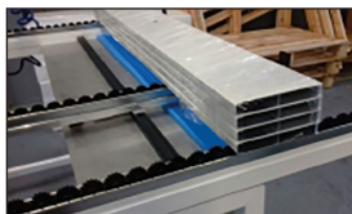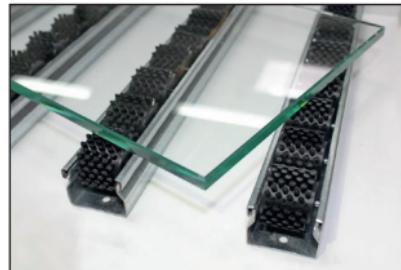

Typical application

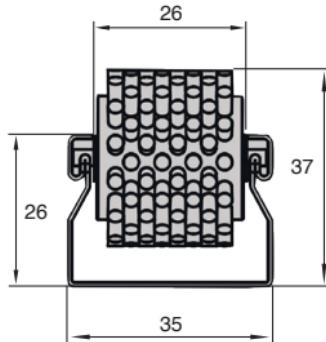


DISCOUNTS

Qty	1+	2+	5+	10+	20+
Disc.	List	-5%	-11%	-14%	On request

Part number	Length L (mm)	Space between rollers (mm)	Nb of rollers	Load-bearing capacity per 1 m track (kg)	Price each.
Low density					
RAG-B30-2000	2000	66	30	25	
High density					
RAG-B60-2000	2000	33	60	50	

Dimension in mm

Our other products

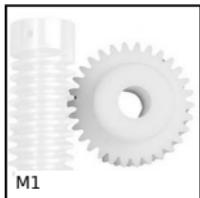

M1
Worm and wheel set,
Machined plastic
(delrin)



RCC_RCX
Spherical tilt washer -
DIN6319, convex



PF60
Worm and wheel gear
reducer, up to 118
Nm



D19_D29
Compression springs
in metre length
stainless steel, by the
metre



LWH
High rigidity linear
slide, Chariot - from
9320 N to 71300 N



SBS_L
Chain link, Stainless
steel



ES
Support base (tripod),
Plastic




UTKpwcr
Utilitrak® 3 wheels
carriage, Polymer
roller carriage



CHAE6555
Decorative screwed
hinge, Aluminium



BIMSS
Indexing plunger mini,
miniature - Stainless
steel

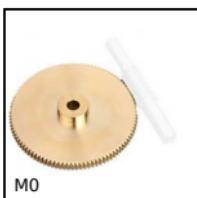

M0
Worm and wheel set,
Bronze



PRF_CH
Cable-carrier chain for
aluminium profile,
Supplied in metre
lengths

Complementary products



RAGFLOW
Floway2® roller track,
Roller track



RAGFLOWsupport
Floway2® Roller track
accessory, Roller
track support



RAG
Roller guide,