

Manual bevel gearbox



RAM30

Manual torque up to 4 Nm




- **Manually operated bevel gearbox**
- Ratios from 1:1
- **Materials:**
 - Housing: Glass fibre reinforced PA6
 - Bevel gears: Case hardened steel

Info


- Not suitable for motorised applications

Accessories

- MBEX handle (tome 2 p.249)
- AHX hexagonal shaft (tome 2 p.248)

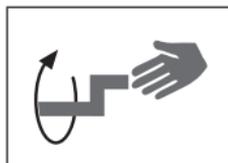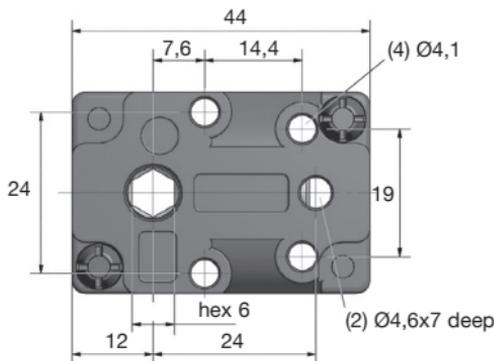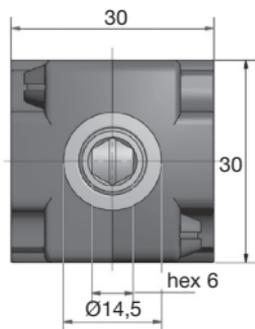

For manual operation only

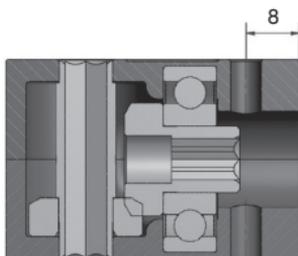

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Ratio	Input	Output	Max torque (Nm)	Stock*	Price each 1 to 9
RAM30-1	1:1	hex 6mm	hex 6mm	4	✓	65,57 €

*Depending of availability - Dimensions in mm



Manual bevel gearbox

Manual torque up to 6 Nm

RAM35





- **Manually operated bevel gearbox**
- Ratios from 1:1 to 2:1
- Materials:
Housing: Glass fibre reinforced PA6
Bevel gears: Case hardened steel

Info

- Not suitable for motorised applications

Accessories

- MBEX handle (**tome 2 p.249**)
- AHEx hexagonal shaft (**tome 2 p.248**)

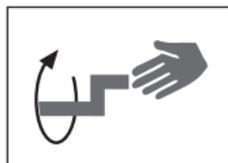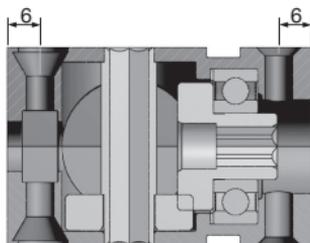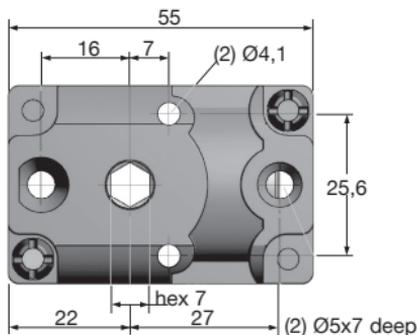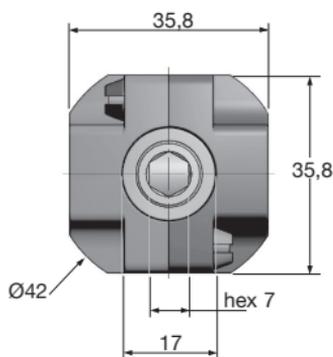

For manual operation only

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List	-5%	-15%	On request	

Part number	Ratio	Input	Output	Max torque (Nm)	Stock*	Price each 1 to 9
RAM35-1	1:1	hex 7mm	hex 7mm	6	✓	74,64 €
RAM35-2	2:1	hex 7mm	hex 7mm	6	✓	62,09 €

*Depending of availability - Dimensions in mm