

# Manual bevel gearbox



## RAM30

## Manual torque up to 4 Nm




- **Manually operated bevel gearbox**
- Ratios from 1:1
- **Materials:**
  - Housing: Glass fibre reinforced PA6
  - Bevel gears: Case hardened steel

### Accessories


- MBEX handle
- AHEX hexagonal shaft

### Info

- Not suitable for motorised applications

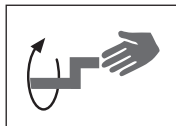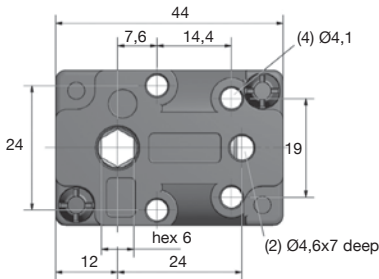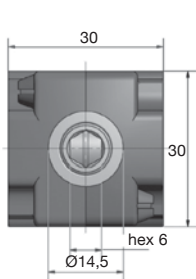

For manual applications

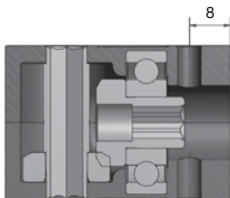

### DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Ratio	Input	Output	Max torque (Nm)	Price each 1 to 9
RAM30-1	1:1	hex 6mm	hex 6mm	4	39,10 €

Dimensions in mm


## Our other products



Weld-on hinge with flat end, Steel



Spur gear - precision range, Stainless steel 303

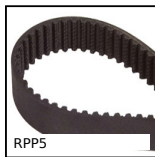

RPP heavy duty timing belt, RPP5



Eco range Spur gear, Steel C45



Stainless steel AC asynchronous motor 0.55 - 0.75kW, 0.55 to 0.75kW



Combined bearing with inner ring, Axial load in both directions



Utilitak® V rail, V rail



Accessories, Turntable



Catch-plate for latch, Catch-plate



Universal adjustable guide support bracket, Stainless steel



Steel spur gear, Steel 20NCD2



Worm and wheel gear reducer, up to 57 Nm - Integrated torque limiter

## Complementary products



Hexagonal shaft, Hexagonal shaft



Hexagonal ended handle, Hexagonal ended handle