

# Manual bevel gearbox



## RAM30

## Manual torque up to 4 Nm

- Manually operated bevel gearbox

- Ratios from 1:1

- Materials:

Housing: Glass fibre reinforced PA6  
Bevel gears: Case hardened steel




### Accessories

- MBEX handle


- AHEX hexagonal shaft

### Info

- Not suitable for motorised applications

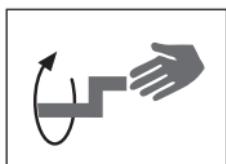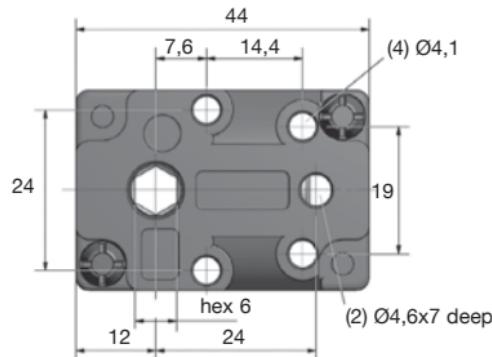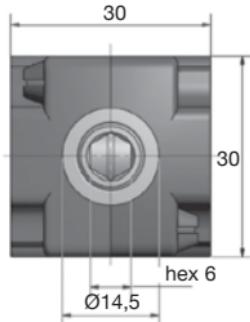

For manual  
applications

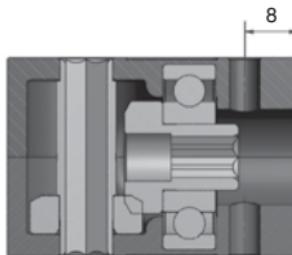

### DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Ratio	Input	Output	Max torque (Nm)	Price each 1 to 9
RAM30-1	1:1	hex 6mm	hex 6mm	4	39,10 €

Dimensions in mm

## Our other products



NCT

Square tube connector, Fixed angle



BABFCFO

Ball pin socket, Mounting collar with a round flange



PCS75K

Chain sprocket with hardened teeth, 19.05mm (DIN12B-1)



BS3

Panamech, Multi-Beam stainless steel, Stainless steel - with set screw



H0

Crossed helical gear crossed axis at 90°, Steel 20NCD2



WSS

Symmetrical S shaped hook, Steel



P20

Worm and wheel gear reducer, up to 5 Nm



T10\_21N1F

T type timing pulley, Economy range - T10 moulded plastic (nylon)



BLHM40

Right angled gearbox, double output shafts, up to 10.3 Nm



BSP

Compact precision slide, from 156 N to 980 N



BPMc

Stainless steel slotted spring plunger with ceramic ball tip, 303 St...



SVG

Adjustable latch clamp with strike plate, Stroke from 118mm to 130,5mm

## Complementary products



AHEX

Hexagonal shaft, Hexagonal shaft



MBEX

Hexagonal ended handle, Hexagonal ended handle