

Manual bevel gearbox



RAM30

Manual torque up to 4 Nm




- **Manually operated bevel gearbox**
- Ratios from 1:1
- **Materials:**
 - Housing: Glass fibre reinforced PA6
 - Bevel gears: Case hardened steel

Accessories


- MBEX handle
- AHEX hexagonal shaft

Info

- Not suitable for motorised applications

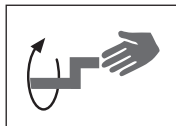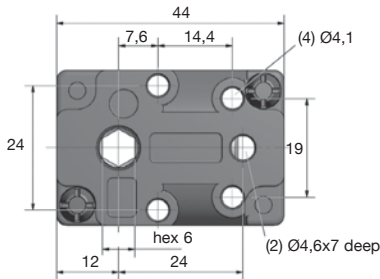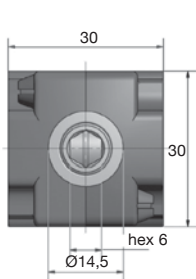

For manual applications

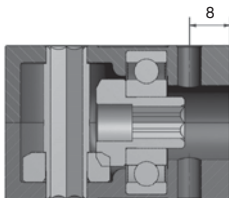

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Ratio	Input	Output	Max torque (Nm)	Price each 1 to 9
RAM30-1	1:1	hex 6mm	hex 6mm	4	39,10 €

Dimensions in mm

Our other products



PSPD18

Flexible tube handle,
Black PVC



MLY

Bow shackle with eye
bolt, Steel



PHT

Pull handle, Up to 250
°C



NTM

Nylon tipped set
screw, Nylon-point



PDR-RD

Mounting feet with
integrated castors,
Offset castor



BAG-MI

Split shaft collar with
clamp lever, Steel



AT5courroie

AT type timing belt,
AT5 Steel cored
polyurethane



CM_CO

Tools Hygienic Usit®
and Hygienic
Design®, Protective
inserts for ...



ESCON

Speed controller 5A
accessories, USB
cable for PC link



OP6

Mechanical digital
position indicator, 5
numbers



AT5P_AT10P

Connecting plate for
AT type timing belts,
AT10



SBF

Sealed flange bearing
unit for Food Industry,
cover

Complementary products



AHEX

Hexagonal shaft,
Hexagonal shaft



MBEX

Hexagonal ended
handle, Hexagonal
ended handle