

Manual bevel gearbox



RAM30

Manual torque up to 4 Nm




- **Manually operated bevel gearbox**
- Ratios from 1:1
- **Materials:**
 - Housing: Glass fibre reinforced PA6
 - Bevel gears: Case hardened steel

Accessories


- MBEX handle
- AHEX hexagonal shaft

Info

- Not suitable for motorised applications

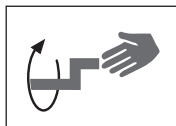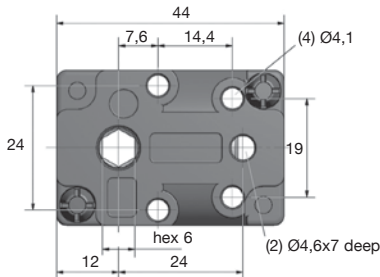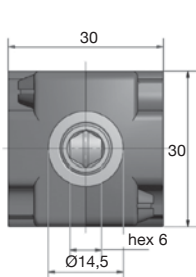

For manual applications

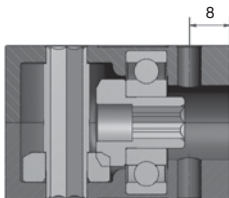

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Ratio	Input	Output	Max torque (Nm)	Price each 1 to 9
RAM30-1	1:1	hex 6mm	hex 6mm	4	39,10 €

Dimensions in mm

Our other products



KBS_UU
Stainless steel closed precision linear bearing, Precision - staine...



PTA80
Articulated levelling foot, pressed base Ø80, Ø 80



SLB5
Stainless steel indexing plunger, Stainless steel



ES
Simple support base (bipod), Plastic



NDS20
Double cross clamp, Parallel



NPTR10
Adjustable cross clamp, Adjustable



H3
Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



STC
Shock Absorber - stop collar, Universal flange




T2
T type timing belt, T2.5 Steel cored polyurethane



DOMI50
Accessories, Turntable



 PLM-SC
Magnetic stud with threaded hole. With threaded hole



PRZ
Wear strip for slat top chain, Z profile to be clipped

Complementary products



AHX
Hexagonal shaft, Hexagonal shaft



MBEX
Hexagonal ended handle, Hexagonal ended handle