



Manual bevel gearbox

Manual torque up to 6 Nm

RAM35




- **Manually operated bevel gearbox**
- Ratios from 1:1 to 2:1
- Materials:
Housing: Glass fibre reinforced PA6
Bevel gears: Case hardened steel

Accessories


- MBEX handle
- AHEX hexagonal shaft

Info

- Not suitable for motorised applications

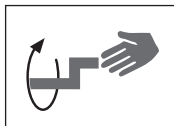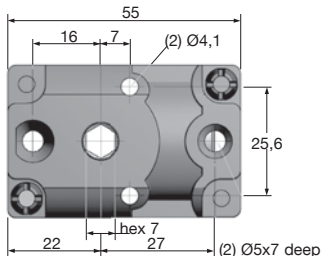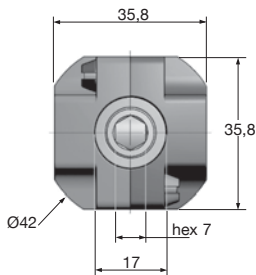

For manual applications

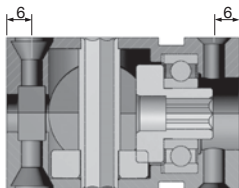

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Ratio	Input	Output	Max torque (Nm)	Price each 1 to 9
RAM35-1	1:1	hex 7mm	hex 7mm	6	50,60 €
RAM35-2	2:1	hex 7mm	hex 7mm	6	50,60 €

 
Dimensions in mm

Our other products



TUBE25_25

Square Tube,
Aluminium or
Stainless steel




BMF

Knurled knob -
female, Knurled -
through threaded



MSP3815

Masterplate®
glueable insert
rectangular,
rectangular with

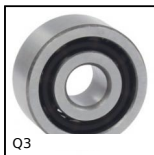

Q3

Double row angular
contact ball bearing,
Angular contact -
Steel



BABA

Ball pin lifting ring,
Steel



CHAR5050_Z

Spring hinge, screwed



SSDB

Stainless steel bevel
gear, 2:1




PMB

Anti-vibration
machine mount, Oval
base plate



SH2

Parallel axis helical
gear, Steel 20NCD2

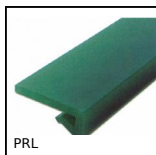

PRL

Wear strip for slat top
chain, L profile to be



BPM

Slotted spring plunger
with ball tip, Stainless



RAM35

Manual bevel
gearbox, Bevel

Complementary products



AHEX

Hexagonal shaft,
Hexagonal shaft



MBEX

Hexagonal ended
handle, Hexagonal
ended handle