



Manual bevel gearbox

Manual torque up to 6 Nm

RAM35





- **Manually operated bevel gearbox**
- Ratios from 1:1 to 2:1
- Materials:
Housing: Glass fibre reinforced PA6
Bevel gears: Case hardened steel

Accessories

- MBEX handle
- AHEX hexagonal shaft

Info

- Not suitable for motorised applications

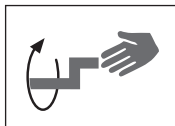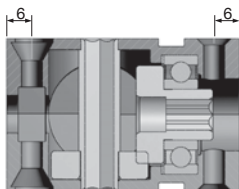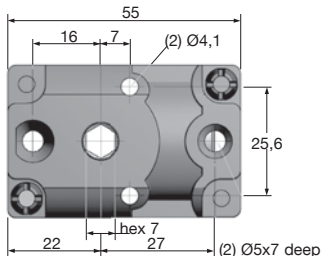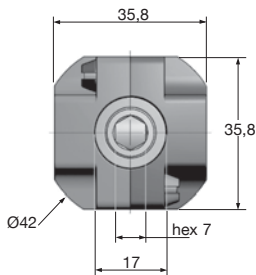

For manual applications

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request


Part number	Ratio	Input	Output	Max torque (Nm)	Price each 1 to 9
RAM35-1	1:1	hex 7mm	hex 7mm	6	50,60 €
RAM35-2	2:1	hex 7mm	hex 7mm	6	50,60 €

Dimensions in mm

Our other products



 Hexagonal shaft,
Hexagonal shaft



Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)



Spur gear - precision
range, Pre-hardened
Steel 35NCD6



Stainless steel bevel
gear, 2:1



Utilitak® V rail, V rail



Square hinge with
riveted pin, not
drilled, Square with
riveted pin,...



Asynchronous AC
Motor, 0.18 to 0.55kW



Domino 120
adjustable slide, Slide
DOMILINE 120



Stainless steel gas
spring, Stainless steel



Stainless steel
miniature ball transfer
unit, Miniature to



Adjustable cross
clamp, Adjustable



Slotted spring plunger
with ball tip, Stainless
steel 303

Complementary products



Hexagonal shaft,
Hexagonal shaft



Hexagonal ended
handle, Hexagonal
ended handle