



Manual bevel gearbox

Manual torque up to 6 Nm

RAM35





- **Manually operated bevel gearbox**
- Ratios from 1:1 to 2:1
- Materials:
Housing: Glass fibre reinforced PA6
Bevel gears: Case hardened steel

Accessories

- MBEX handle
- AHEX hexagonal shaft

Info

- Not suitable for motorised applications

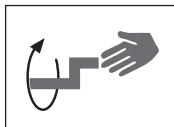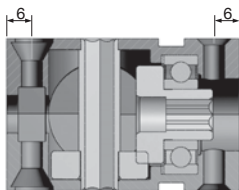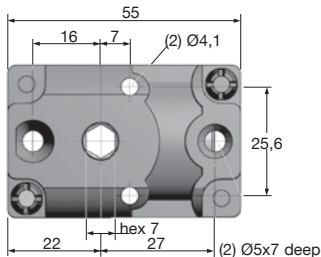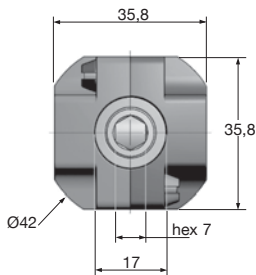

For manual applications

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Ratio	Input	Output	Max torque (Nm)	Price each 1 to 9
RAM35-1	1:1	hex 7mm	hex 7mm	6	50,60 €
RAM35-2	2:1	hex 7mm	hex 7mm	6	50,60 €

Dimensions in mm

Our other products



CHINV2

Invisible hinge,
Invisible - Opening up to 125°



VQTplqp

Quarter-turn clamp
lock - Clamping plate,
Wall mounting



RT61ss

Self-centering locking
Assembly,
Medium/low torque



 
SDCcs

Positioning sleeve for
indexing pin, For pin
Ø4 to Ø12



ACLBS

Closing system for
aluminium profile,
Spacer for spherical
ended stop



AC

Strike for toggle latch,
15mm



GMC_GMK_BR

Guiding profile clamp,
Flat or rounded



TBEbase

Base plate for
economic mini-table,
Allows X-Y cross
tables



CFF_SS

Female rod ends DIN
ISO12240-4, Stainless
steel / bronze -



ACLAPA

Magnetic stop for
aluminium profile,
Magnetic stop



TBD

Manual leadscrew
table with opposing
threads, 20kg



TBE16

Economic mini-table
with trapezoidal
leadscrew, 5kg

Complementary products



AHEx

Hexagonal shaft,
Hexagonal shaft



MBEx

Hexagonal ended
handle, Hexagonal
ended handle