

Steel/steel or stainless steel/stainless steel contact **RAS RASs**



- **Conforms to DIN 71802**
- Working angle: Lateral $\pm 15^\circ$
Front to back $\pm 18^\circ$
- Materials:
passivated galvanised steel
stainless steel 303
- Retained in housing by a fastener
- For the left hand threaded version, only the female part has a left hand thread

steel or stainless steel



Advantages

- Wear resistant

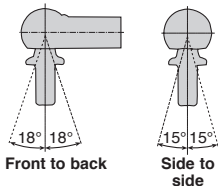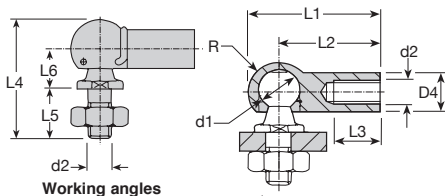

Sizes	Fixing A/F	Max. radial and axial static force. kp
M5	7	30
M6	8	70
M8	11	150
M10	13	200
M12	13	200


DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-15%	-20%	-30%	On request

Part number	Steel	S. steel	d1	d2	D4	L1	L2	L3	L4	L5	L6	R	Stock* S. Steel	Steel	Price each 1 to 5	Steel	Stainless steel	
Right hand thread																		
RAS5		RAS5/SS	8	M5	8	28,5	22,0	10,2	25,0	10,2	9,0	6,4	✓	✓	4,79 €	7,05 €		
RAS6		RAS6/SS	10	M6	10	32,5	25,0	11,5	30,0	12,5	11,0	7,5	✓	✓	4,97 €	7,22 €		
RAS8		RAS8/SS	13	M8	13	39,5	30,0	14,0	38,0	16,5	13,0	9,7	✓	✓	6,06 €	9,21 €		
RAS10		RAS10/SS	16	M10	16	47,0	35,0	15,5	47,5	20,0	16,0	12,0	✓	✓	8,17 €	16,30 €		
RAS12		RAS12/SS	16	M12	16	47,0	35,0	15,0	47,5	20,0	16,0	12,0	✓	✓	11,51 €	19,10 €		
Left hand thread																		
RAS5L	-		8	M5	8	28,5	22,0	10,5	25,0	10,2	9,0	6,4	✓	-	5,54 €	-		
RAS6L	-		10	M6	10	32,5	25,0	11,5	30,0	12,5	11,0	7,5	✓	-	5,59 €	-		
RAS8L	-		13	M8	13	39,5	30,0	14,0	38,0	16,5	13,0	9,7	✓	-	6,70 €	-		
RAS10L	-		16	M10	16	47,0	35,0	15,5	47,5	20,0	16,0	12,0	✓	-	8,82 €	-		
RAS12L	-		16	M12	16	47,0	35,0	15,0	47,5	20,0	16,0	12,0	✓	-	13,66 €	-		

*Depending on availability - ** On price list 2010 - Dimensions in mm

 Our other products



EPRF

High helix leadscrew,
Flanged nut - up to
40mm per rotation




BLH70

Right angled gearbox,
from 26 to 128 Nm



MSP38

 Masterplate®
glueable insert Ø38,
Cylindrical Ø38 with
tapped ins...




GMC

Flat profile - Round
guide, Flat profile -
round guide



RFK58B

 Hypoid gearbox -
Stainless steel, up to
500 Nm




R_RR

Narrow spur rack,
Steel



PCS37K

Chain sprocket with
hardened teeth,
9.525mm (DIN06B-1)

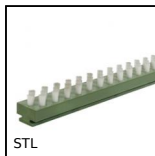

STL

Guidance brush -
Brush, Brush



CHAR16046

Spring hinge, screwed



BDP2R

Adjustable support
arm, Increased grip



RHTtcss

High Temperature
Castor, up to 200kg



DTR

Chain idler sprocket,
Chain idler sprocket -
Plastic

Complementary products



IBJ

180° ball and socket
joints, Steel



CNA-CNG

Right angled
mounting plate, Right
angled mounting
plate for ball jo...



COA-COG

Surface mounting
plate, Surface
mounting plate for
ball joint



IBJss

Ball and socket joint,
Stainless steel