

Steel/steel or stainless steel/stainless steel contact **RAS RASs**



- **Conforms to DIN 71802**
- Working angle: Lateral  $\pm 15^\circ$   
Front to back  $\pm 18^\circ$
- Materials:  
passivated galvanised steel  
stainless steel 303
- Retained in housing by a fastener
- For the left hand threaded version, only the female part has a left hand thread

steel or stainless steel



**Advantages**

- Wear resistant

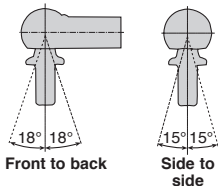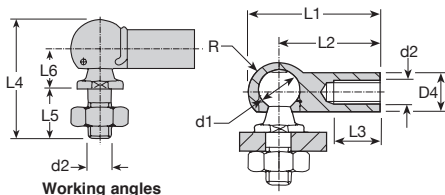

Sizes	Fixing A/F	Max. radial and axial static force. kp
M5	7	30
M6	8	70
M8	11	150
M10	13	200
M12	13	200

**DISCOUNTS**

Qty	1+	6+	20+	40+	60+
Disc.	List	-15%	-20%	-30%	On request

Part number	Steel	S. steel	d1	d2	D4	L1	L2	L3	L4	L5	L6	R	Stock* S. Steel	Steel	Price each 1 to 5	Steel	Stainless steel	
<b>Right hand thread</b>																		
RAS5		RAS5/SS	8	M5	8	28,5	22,0	10,2	25,0	10,2	9,0	6,4	✓	✓	4,79 €	7,05 €		
RAS6		RAS6/SS	10	M6	10	32,5	25,0	11,5	30,0	12,5	11,0	7,5	✓	✓	4,97 €	7,22 €		
RAS8		RAS8/SS	13	M8	13	39,5	30,0	14,0	38,0	16,5	13,0	9,7	✓	✓	6,06 €	9,21 €		
RAS10		RAS10/SS	16	M10	16	47,0	35,0	15,5	47,5	20,0	16,0	12,0	✓	✓	8,17 €	16,30 €		
RAS12		RAS12/SS	16	M12	16	47,0	35,0	15,0	47,5	20,0	16,0	12,0	✓	✓	11,51 €	19,10 €		
<b>Left hand thread</b>																		
RAS5L	-		8	M5	8	28,5	22,0	10,5	25,0	10,2	9,0	6,4	✓	-	5,54 €			
RAS6L	-		10	M6	10	32,5	25,0	11,5	30,0	12,5	11,0	7,5	✓	-	5,59 €			
RAS8L	-		13	M8	13	39,5	30,0	14,0	38,0	16,5	13,0	9,7	✓	-	6,70 €			
RAS10L	-		16	M10	16	47,0	35,0	15,5	47,5	20,0	16,0	12,0	✓	-	8,82 €			
RAS12L	-		16	M12	16	47,0	35,0	15,0	47,5	20,0	16,0	12,0	✓	-	13,66 €			

\*Depending on availability - \*\* On price list 2010 - Dimensions in mm

## Our other products



MDPOT

Potentiometer,



BTESS

Universal stainless steel arm for tensioner, For use in hostile envi...



Q6

Deep groove ball bearing, Steel



GCL

Linear ball slide - Stainless steel balls, Chariot - from 516 N to 8...



PR882

Idler sprocket for slat top chain, Range 882



GP

Spring loaded toggle latch, Standard (GP22-GP23)



SLB

Indexing plunger, steel class 5.8



SHNbr

Hexagonal nut DIN934, Brass




PVL

Small lobed handle, Polyamide



BLHM20

 Right angled gearbox, double output shafts,



GLT2-27

Telescopic drawer runners for groove



GE\_C

Spherical bushing, Hard chromium / PTFE

## Complementary products



IBJ

180° ball and socket joints, Steel



CNA-CNG

Right angled mounting plate, Right angled mounting plate for ball jo...



COA\_COG

Surface mounting plate, Surface mounting plate for ball joint



IBJss

Ball and socket joint, Stainless steel