

Steel/steel or RAS
stainless steel/stainless steel contact RASss


- Conforms to DIN 71802
- Working angle: Lateral $\pm 15^\circ$
- Front to back $\pm 18^\circ$
- Materials:
 - passivated galvanised steel
 - stainless steel 303
- Retained in housing by a fastener
- For the left hand threaded version, only the female part has a left hand thread

steel or
stainless steel




Advantages

- Wear resistant

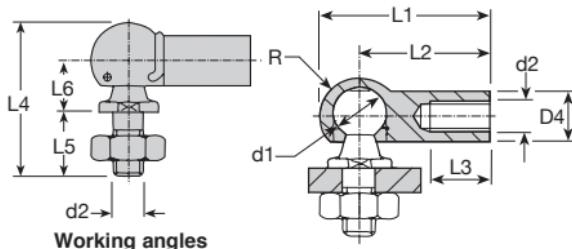

| Sizes | Fixing A/F | Max. radial and axial static force. kp | |
|-------|---------------|--|----------|
| | | Steel | S. steel |
| M5 | 7 | 30 | |
| M6 | 8 | 70 | |
| M8 | 11 | 150 | |
| M10 | 13 | 200 | |
| M12 | 13 | 200 | |

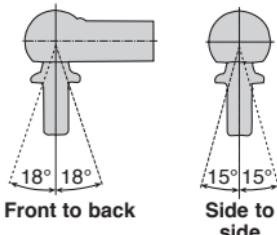

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 40+ | 60+ |
|-------|------|------|------|------|------------|
| Disc. | List | -15% | -20% | -30% | On request |

| Part number | Steel | S. steel | d1 | d2 | D4 | L1 | L2 | L3 | L4 | L5 | L6 | R | Stock [*] Steel | S. Steel | Price each 1 to 5 Stainless steel |
|-------------|-------|----------|----|----|----|----|----|----|----|----|----|---|-----------------------------|-------------|--------------------------------------|
|-------------|-------|----------|----|----|----|----|----|----|----|----|----|---|-----------------------------|-------------|--------------------------------------|

Right hand thread

| | | | | | | | | | | | | | | | |
|-------|----------|----|-----|----|------|------|------|------|------|------|------|---|---|---------|---------|
| RAS5 | RAS5/SS | 8 | M5 | 8 | 28,5 | 22,0 | 10,2 | 25,0 | 10,2 | 9,0 | 6,4 | ✓ | ✓ | 4,79 € | 7,05 € |
| RAS6 | RAS6/SS | 10 | M6 | 10 | 32,5 | 25,0 | 11,5 | 30,0 | 12,5 | 11,0 | 7,5 | ✓ | ✓ | 4,97 € | 7,22 € |
| RAS8 | RAS8/SS | 13 | M8 | 13 | 39,5 | 30,0 | 14,0 | 38,0 | 16,5 | 13,0 | 9,7 | ✓ | ✓ | 6,06 € | 9,21 € |
| RAS10 | RAS10/SS | 16 | M10 | 16 | 47,0 | 35,0 | 15,5 | 47,5 | 20,0 | 16,0 | 12,0 | ✓ | ✓ | 8,17 € | 16,30 € |
| RAS12 | RAS12/SS | 16 | M12 | 16 | 47,0 | 35,0 | 15,0 | 47,5 | 20,0 | 16,0 | 12,0 | ✓ | ✓ | 11,51 € | 19,10 € |

Left hand thread

| | | | | | | | | | | | | | | | |
|--------|---|----|-----|----|------|------|------|------|------|------|------|---|---|---------|---|
| RAS5L | - | 8 | M5 | 8 | 28,5 | 22,0 | 10,5 | 25,0 | 10,2 | 9,0 | 6,4 | ✓ | - | 5,54 € | - |
| RAS6L | - | 10 | M6 | 10 | 32,5 | 25,0 | 11,5 | 30,0 | 12,5 | 11,0 | 7,5 | ✓ | - | 5,59 € | - |
| RAS8L | - | 13 | M8 | 13 | 39,5 | 30,0 | 14,0 | 38,0 | 16,5 | 13,0 | 9,7 | ✓ | - | 6,70 € | - |
| RAS10L | - | 16 | M10 | 16 | 47,0 | 35,0 | 15,5 | 47,5 | 20,0 | 16,0 | 12,0 | ✓ | - | 8,82 € | - |
| RAS12L | - | 16 | M12 | 16 | 47,0 | 35,0 | 15,0 | 47,5 | 20,0 | 16,0 | 12,0 | ✓ | - | 13,66 € | - |

*Depending on availability - ** On price list 2010 - Dimensions in mm


Our other products



CHB
Worm and wheel gear reducer, up to 22 Nm



BTC_M
End cap with threaded insert for square tube, With threaded insert

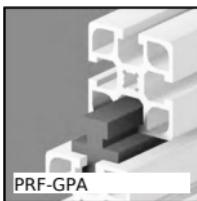

PRF-GPA
Guide for aluminium profile, Parallel rails




SBRtool
Chain tool, Drive chain maintenance tools



QNUP
Single row cylindrical roller bearing, 1 fixed inner flange and 1 free running



RUR
Wheel, Polyurethane - Aluminium rim (Free running)

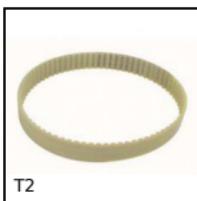

T2
T type timing belt, T2.5 Steel cored polyurethane



CLB_M
Die cast zinc clamping lever - female, Zamak



HBM
Adjustement bushing for half-rail guide,



CHA225
Screwed hinge with threaded insert, 225



CTZYSS
Stainless steel diabolo shaped elasto mount,



PRF_P
Anchor foot for 45x45 profile, Anchor foot

Complementary products



CNA-CNG
Right angled mounting plate, Right angled mounting plate for ball joint...



COA-COG
Surface mounting plate, Surface mounting plate for ball joint



RAS
90° ball and socket joints DIN71802, Stainless steel



IBJ
180° ball and socket joints, Steel