

Steel/steel or stainless steel/stainless steel contact **RAS RASs**


- **Conforms to DIN 71802**
- Working angle: Lateral  $\pm 15^\circ$   
Front to back  $\pm 18^\circ$
- Materials:  
passivated galvanised steel  
stainless steel 303
- Retained in housing by a fastener
- For the left hand threaded version, only the female part has a left hand thread

steel or stainless steel




**Advantages**

- Wear resistant

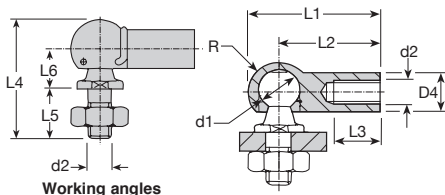

Working angles

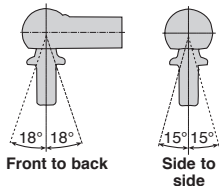

Front to back

Side to side

Sizes	Fixing A/F	Max. radial and axial static force. kp
M5	7	30
M6	8	70
M8	11	150
M10	13	200
M12	13	200

**DISCOUNTS**

Qty	1+	6+	20+	40+	60+
Disc.	List	-15%	-20%	-30%	On request

Part number	Steel	S. steel	d1	d2	D4	L1	L2	L3	L4	L5	L6	R	Stock* S.		Price each 1 to 5	
													Steel	Steel	Steel	Stainless steel
<b>Right hand thread</b>																
RAS5		RAS5/SS	8	M5	8	28,5	22,0	10,2	25,0	10,2	9,0	6,4	✓	✓	4,79 €	7,05 €
RAS6		RAS6/SS	10	M6	10	32,5	25,0	11,5	30,0	12,5	11,0	7,5	✓	✓	4,97 €	7,22 €
RAS8		RAS8/SS	13	M8	13	39,5	30,0	14,0	38,0	16,5	13,0	9,7	✓	✓	6,06 €	9,21 €
RAS10		RAS10/SS	16	M10	16	47,0	35,0	15,5	47,5	20,0	16,0	12,0	✓	✓	8,17 €	16,30 €
RAS12		RAS12/SS	16	M12	16	47,0	35,0	15,0	47,5	20,0	16,0	12,0	✓	✓	11,51 €	19,10 €
<b>Left hand thread</b>																
RAS5L	-		8	M5	8	28,5	22,0	10,5	25,0	10,2	9,0	6,4	✓	-	5,54 €	-
RAS6L	-		10	M6	10	32,5	25,0	11,5	30,0	12,5	11,0	7,5	✓	-	5,59 €	-
RAS8L	-		13	M8	13	39,5	30,0	14,0	38,0	16,5	13,0	9,7	✓	-	6,70 €	-
RAS10L	-		16	M10	16	47,0	35,0	15,5	47,5	20,0	16,0	12,0	✓	-	8,82 €	-
RAS12L	-		16	M12	16	47,0	35,0	15,0	47,5	20,0	16,0	12,0	✓	-	13,66 €	-

\*Depending on availability - \*\* On price list 2010 - Dimensions in mm

## Our other products



DB\_ECO

Bevel gear - Steel  
C43, 2:1



M1

Wheel, Bronze



PTA100

Articulated foot with  
pressed base, Ø 100



DST

Pinion shaft, Stainless  
steel 303



BDP2R

Holding arm,  
Increased grip



LVT

Miniature motorised  
actuator, 1 amper



CLAT

Clamping lever  
Hygienic Usit®,  
Stainless steel



PM3

Worm, Non hardened  
steel



RURp

Wheel pivoting with  
plate, Polyurethane -  
Aluminium rim (Free  
running)



PR820

Idle sprocket, Rangs  
820 and 815



PW\_PWG05

Wheel - precision  
range, Bronze



BPM\_LOK

Slotted spring plunger  
with ball tip, LONG-  
LOK - Stainless steel  
303

## Complementary products



IBJ

Ball and socket joint,  
Steel



CNA-CNG

Gas spring, Right  
angled mounting  
plate for ball joint



COA-COG

Gas spring, Surface  
mounting plate for  
ball joint



IBJss

Ball and socket joint,  
Stainless steel