

Steel/steel or stainless steel/stainless steel contact **RAS RASs**



- **Conforms to DIN 71802**
- Working angle: Lateral $\pm 15^\circ$
Front to back $\pm 18^\circ$
- Materials:
passivated galvanised steel
stainless steel 303
- Retained in housing by a fastener
- For the left hand threaded version, only the female part has a left hand thread

steel or stainless steel



Advantages

- Wear resistant

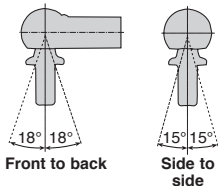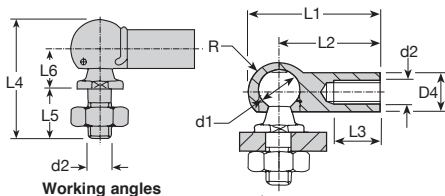

Sizes	Fixing A/F	Max. radial and axial static force. kp
M5	7	30
M6	8	70
M8	11	150
M10	13	200
M12	13	200

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-15%	-20%	-30%	On request

Part number	Steel	S. steel	d1	d2	D4	L1	L2	L3	L4	L5	L6	R	Stock* S. Steel	Steel	Price each 1 to 5	Steel	Stainless steel	
Right hand thread																		
RAS5		RAS5/SS	8	M5	8	28,5	22,0	10,2	25,0	10,2	9,0	6,4	✓	✓	4,79 €	7,05 €		
RAS6		RAS6/SS	10	M6	10	32,5	25,0	11,5	30,0	12,5	11,0	7,5	✓	✓	4,97 €	7,22 €		
RAS8		RAS8/SS	13	M8	13	39,5	30,0	14,0	38,0	16,5	13,0	9,7	✓	✓	6,06 €	9,21 €		
RAS10		RAS10/SS	16	M10	16	47,0	35,0	15,5	47,5	20,0	16,0	12,0	✓	✓	8,17 €	16,30 €		
RAS12		RAS12/SS	16	M12	16	47,0	35,0	15,0	47,5	20,0	16,0	12,0	✓	✓	11,51 €	19,10 €		
Left hand thread																		
RAS5L	-		8	M5	8	28,5	22,0	10,5	25,0	10,2	9,0	6,4	✓	-	5,54 €			
RAS6L	-		10	M6	10	32,5	25,0	11,5	30,0	12,5	11,0	7,5	✓	-	5,59 €			
RAS8L	-		13	M8	13	39,5	30,0	14,0	38,0	16,5	13,0	9,7	✓	-	6,70 €			
RAS10L	-		16	M10	16	47,0	35,0	15,5	47,5	20,0	16,0	12,0	✓	-	8,82 €			
RAS12L	-		16	M12	16	47,0	35,0	15,0	47,5	20,0	16,0	12,0	✓	-	13,66 €			


*Depending on availability - ** On price list 2010 - Dimensions in mm

Our other products



CHAsb89

 Hinge without pin,
Plastic hinge



TBL

Mini leadscrew table
with metric thread,
Base plate



PTA40

Articulated foot with
solid base foot \varnothing 40,
30000N



PTRSS

Idler chain sprocket,
For hostile
environments



 
WFRM

Flanged polymer nut,
Polymer (Iglidur®) - 1
thread



MDB_MTB

Moulded plastic bevel
gear (nylon), 2:1



H1

Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)



E60B

Right angle helical
reducers, from 4.50 to
24 Nm



AT10-25ECO

AT type timing pulley,
Economy range -




BLH40

Right angled gearbox,
from 3 to 10.30 Nm



CHAM5270SS

 Marine hinge for
welding/screw



PRF-GPA

Guide for aluminium
profile, Parallel rails

Complementary products



CNA-CNG

Right angled
mounting plate, Right
angled mounting
plate for ball jo...



COA-COG

Surface mounting
plate, Surface
mounting plate for
ball joint



RAS

90° ball and socket
joints DIN71802,
Stainless steel



IBJ

180° ball and socket
joints, Steel