


Castor with mounting plate

For medium loads up to 110kg

RBGPL

- **Light industrial swivel castor with central hole**
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Materials:
 - Top plate: pressed steel sheet, protected by bright zinc plating
 - Grey vulcanized rubber wheel 85°Shore (see **RBG**)
 - Smooth central bore
- Working temperature range: - 20°C to + 60°C

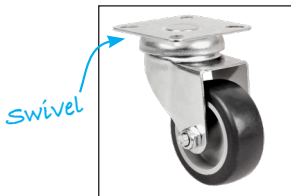

Advantages

- Soft, silent wheel
- Absorbs shock and vibration
- Will not damage floors



ØD



B



H



L



M



ØT



ØK

DISCOUNTS

Qty	1+	10+	30+
Disc. List	-5%		On request

Part number	ØD	B	H	L	M	ØT	Swivel interference ØK	Max load (kg)	Stock*	Price each 1 to 9
Fixed										
RBG50/PL/F	50	22	76	67x52	50x36	6	-	45	✓	3,12 €
RBG60/PL/F	60	24	85	67x52	50x36	6	-	55	✓	3,35 €
RBG80/PL/F	80	23	106	65x54	50x36	6	-	65	✓	4,37 €
RBG100/PL/F	100	26	122	67x60	46x46	6	-	75	✓	5,88 €
RBG125/PL/F	125	32	157	95x68	73x44	8	-	110	✓	7,10 €
Swivel										
RBG50/PL/P	50	22	76	64x48	50x36	6	98	45	✓	4,16 €
RBG60/PL/P	60	24	85	64x48	50x36	6	110	55	✓	4,93 €
RBG80/PL/P	80	23	106	64x48	50x36	6	138	65	✓	6,31 €
RBG100/PL/P	100	26	123	64x48	50x36	6	166	75	✓	7,58 €
RBG125/PL/P	125	32	161	90x70	70x50	8	216	110	✓	14,55 €
Swivel with double lock										
RBG50/PL/PDB	50	22	76	64x48	50x36	6	172	45	✓	5,79 €
RBG60/PL/PDB	60	24	85	64x48	50x36	6	172	55	✓	6,17 €
RBG80/PL/PDB	80	23	106	64x48	50x36	6	188	65	✓	7,75 €
RBG100/PL/PDB	100	26	123	64x48	50x36	6	188	75	✓	9,05 €
RBG125/PL/PDB	125	32	161	90x70	70x50	8	220	110	✓	16,15 €

*Depending on availability - Dimensions in mm

Our other products



PSG125HC

Skive hobbed spur gears - precision range, Case hardened steel 20NCD2



MFB

Flexible bellows coupling, Aluminium and Bronze - With set screw



GLT3-76

Telescopic drawer,



UTKpwcr

Utilitrak® 3 wheels carriage, Polymer roller carriage



LC

Friction clutch, 190 to 1800 Nm



PR40

Articulated foot Ø50, Ø 50



CHAR7530

Spring hinge, welded



PRF_PL_9090

Joining plate for aluminium profile, joint plate - 90x90 mm



CLM

Male clevis end, Stainless steel short




BSP

Compact precision slide, from 156 N to 1800 N



RCX-6

Spherical tilt washer - DIN6319, convex

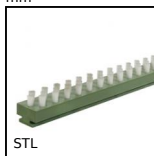

STL

Guidance brush - Brush, Brush

Complementary products



RBNtc

Swivel castor with central hole, Steel - rubber - with double brake



RPCpl

Swivel castor with double brake, Steel - Polyamide



RPCplss

Swivel castor with double brake, Stainless steel - Polyamide



RBG

Wheel, Grey rubber - Polypropylene rim