


Castor with mounting plate

For medium loads up to 110kg

RBGPL

- **Light industrial swivel castor with central hole**
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Materials:
 - Top plate: pressed steel sheet, protected by bright zinc plating
 - Grey vulcanized rubber wheel 85°Shore (see **RBG**)
 - Smooth central bore
- Working temperature range: - 20°C to + 60°C

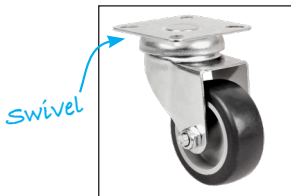

Advantages

- Soft, silent wheel
- Absorbs shock and vibration
- Will not damage floors



ØD



B



H



L



M



ØT



ØK

DISCOUNTS

Qty	1+	10+	30+
Disc. List	-5%		On request

Part number	ØD	B	H	L	M	ØT	Swivel interference load (kg)	Max load (kg)	Stock*	Price each 1 to 9
Fixed										
RBG50/PL/F	50	22	76	67x52	50x36	6	-	45	✓	3,12 €
RBG60/PL/F	60	24	85	67x52	50x36	6	-	55	✓	3,35 €
RBG80/PL/F	80	23	106	65x54	50x36	6	-	65	✓	4,37 €
RBG100/PL/F	100	26	122	67x60	46x46	6	-	75	✓	5,88 €
RBG125/PL/F	125	32	157	95x68	73x44	8	-	110	✓	7,10 €
Swivel										
RBG50/PL/P	50	22	76	64x48	50x36	6	98	45	✓	4,16 €
RBG60/PL/P	60	24	85	64x48	50x36	6	110	55	✓	4,93 €
RBG80/PL/P	80	23	106	64x48	50x36	6	138	65	✓	6,31 €
RBG100/PL/P	100	26	123	64x48	50x36	6	166	75	✓	7,58 €
RBG125/PL/P	125	32	161	90x70	70x50	8	216	110	✓	14,55 €
Swivel with double lock										
RBG50/PL/PDB	50	22	76	64x48	50x36	6	172	45	✓	5,79 €
RBG60/PL/PDB	60	24	85	64x48	50x36	6	172	55	✓	6,17 €
RBG80/PL/PDB	80	23	106	64x48	50x36	6	188	65	✓	7,75 €
RBG100/PL/PDB	100	26	123	64x48	50x36	6	188	75	✓	9,05 €
RBG125/PL/PDB	125	32	161	90x70	70x50	8	220	110	✓	16,15 €

*Depending on availability - Dimensions in mm

Our other products



Stainless steel knurled thumb nut, Knurled



Chain sprocket - Stainless steel, 9.525 (DIN 06B-1)



Precision locknut, Precision locknut



Single universal joint, Normal duty



Indexing plunger for sheets, For sheet metal



Pull handle, Steel



Fixed castor with plate, Stainless steel - Polyamide



Parallel axis helical gear, Machined plastic (delrin)



Clevis components, short version,



Worm and wheel gear reducer, up to 540



Drylin R® linear bearing housing,



Tensioner pulley, For round belts

Complementary products



Fixed castor with plate, Steel - Polyamide



Fixed castor with plate, Steel - rubber



Wheel, Grey rubber - Polypropylene rim



Fixed castor with plate, Polyurethane - Aluminium rim (Free running)