


Castor with mounting plate

For medium loads up to 110kg

RBGPL

- **Light industrial swivel castor with central hole**
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Materials:
 - Top plate: pressed steel sheet, protected by bright zinc plating
 - Grey vulcanized rubber wheel 85°Shore (see **RBG**)
 - Smooth central bore
- Working temperature range: - 20°C to + 60°C

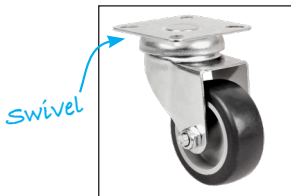

Advantages

- Soft, silent wheel
- Absorbs shock and vibration
- Will not damage floors



ØD



B



H



L



M



ØT



ØK

DISCOUNTS

Qty	1+	10+	30+
Disc. List	-5%		On request

Part number	ØD	B	H	L	M	ØT	Swivel interference ØK	Max load (kg)	Stock*	Price each 1 to 9
Fixed										
RBG50/PL/F	50	22	76	67x52	50x36	6	-	45	✓	3,12 €
RBG60/PL/F	60	24	85	67x52	50x36	6	-	55	✓	3,35 €
RBG80/PL/F	80	23	106	65x54	50x36	6	-	65	✓	4,37 €
RBG100/PL/F	100	26	122	67x60	46x46	6	-	75	✓	5,88 €
RBG125/PL/F	125	32	157	95x68	73x44	8	-	110	✓	7,10 €
Swivel										
RBG50/PL/P	50	22	76	64x48	50x36	6	98	45	✓	4,16 €
RBG60/PL/P	60	24	85	64x48	50x36	6	110	55	✓	4,93 €
RBG80/PL/P	80	23	106	64x48	50x36	6	138	65	✓	6,31 €
RBG100/PL/P	100	26	123	64x48	50x36	6	166	75	✓	7,58 €
RBG125/PL/P	125	32	161	90x70	70x50	8	216	110	✓	14,55 €
Swivel with double lock										
RBG50/PL/PDB	50	22	76	64x48	50x36	6	172	45	✓	5,79 €
RBG60/PL/PDB	60	24	85	64x48	50x36	6	172	55	✓	6,17 €
RBG80/PL/PDB	80	23	106	64x48	50x36	6	188	65	✓	7,75 €
RBG100/PL/PDB	100	26	123	64x48	50x36	6	188	75	✓	9,05 €
RBG125/PL/PDB	125	32	161	90x70	70x50	8	220	110	✓	16,15 €

*Depending on availability - Dimensions in mm

Our other products



TCLar

Automatic chain tensioner, With wide guide



VRCl

Retaining clamp, single sided, Single sided



AT5courroie

AT type timing belt, AT5 Steel cored polyurethane



PFM

Fixed levelling foot, Flanged plate



DIV_SS

Stainless steel locking bolt, With grip - Stainless steel



GARQT

Quarter turn lock pin for clamping, Quarter turn




CHA35

Hinge for aluminium profile, Hinge



INS_BR

 Self tapping brass insert, Brass



PRF_LIS

Door seal for aluminium profile, Black NBR



PRF-P

Aluminium profile feet support, For feet or casters



GG1

Ground spur gear, Heat treated steel



BOX-CSss

Hose clamp, Box set of stainless steel hose clamps

Complementary products



RPCplss

Swivel castor with plate, Stainless steel - Polyamide



RPCpl

Swivel castor with plate, Steel - Polyamide



RBG

Wheel, Grey rubber - Polypropylene rim



RBNpl

Swivel castor with plate, Steel - rubber