


# Castor with mounting plate

For medium loads up to 110kg

**RBGPL**

- **Light industrial swivel castor with central hole**
- Swivel system uses two ball races
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Materials:
  - Top plate: pressed steel sheet, protected by bright zinc plating
  - Grey vulcanized rubber wheel 85°Shore (see **RBG**)
  - Smooth central bore
- Working temperature range: - 20°C to + 60°C

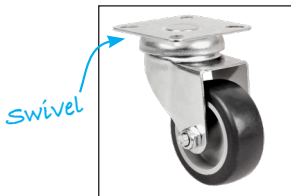

## Advantages

- Soft, silent wheel
- Absorbs shock and vibration
- Will not damage floors



ØD



B



H



L



M



ØT



ØK

## DISCOUNTS

Qty	1+	10+	30+
Disc. List	-5%		On request

Part number	ØD	B	H	L	M	ØT	Swivel interference ØK	Max load (kg)	Stock*	Price each 1 to 9
<b>Fixed</b>										
RBG50/PL/F	50	22	76	67x52	50x36	6	-	45	✓	3,12 €
RBG60/PL/F	60	24	85	67x52	50x36	6	-	55	✓	3,35 €
RBG80/PL/F	80	23	106	65x54	50x36	6	-	65	✓	4,37 €
RBG100/PL/F	100	26	122	67x60	46x46	6	-	75	✓	5,88 €
RBG125/PL/F	125	32	157	95x68	73x44	8	-	110	✓	7,10 €
<b>Swivel</b>										
RBG50/PL/P	50	22	76	64x48	50x36	6	98	45	✓	4,16 €
RBG60/PL/P	60	24	85	64x48	50x36	6	110	55	✓	4,93 €
RBG80/PL/P	80	23	106	64x48	50x36	6	138	65	✓	6,31 €
RBG100/PL/P	100	26	123	64x48	50x36	6	166	75	✓	7,58 €
RBG125/PL/P	125	32	161	90x70	70x50	8	216	110	✓	14,55 €
<b>Swivel with double lock</b>										
RBG50/PL/PDB	50	22	76	64x48	50x36	6	172	45	✓	5,79 €
RBG60/PL/PDB	60	24	85	64x48	50x36	6	172	55	✓	6,17 €
RBG80/PL/PDB	80	23	106	64x48	50x36	6	188	65	✓	7,75 €
RBG100/PL/PDB	100	26	123	64x48	50x36	6	188	75	✓	9,05 €
RBG125/PL/PDB	125	32	161	90x70	70x50	8	220	110	✓	16,15 €


\*Depending on availability - Dimensions in mm

## Our other products



CFF

Female rod ends DIN ISO12240-4, Steel / bronze

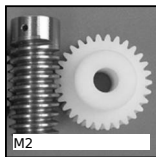

M2

Worm and wheel set, Machined plastic (delrin)



CHA38\_SS

Stainless steel face frame hinge, Surface mount



HTD8M\_30

HTD Heavy duty timing pulley, HTD8 Cast



 
BABreceptacle

Ball pin socket, Socket



GLB

Small 6 lobe female handle, Technopolymer - Stainless steel



RPPM

RPP type belt per metre, RPP8 Steel cored polyurethane



PFM

Fixed levelling foot, Flanged plate



BPHF

Ball transfer unit push fit, Heavy



CHMX\_CHMDX

Shaft for worm and wheel reducer CHMR



APB\_BOU

Protective cap, Safety cap



PRF\_JL5

Lip seal for panel, Door seal - Ø 5mm

## Complementary products



RPCpl

Fixed castor with plate, Steel - Polyamide



RBNpl

Fixed castor with plate, Steel - rubber



RBG

Wheel, Grey rubber - Polypropylene rim



RURp

Fixed castor with plate, Polyurethane - Aluminium rim (Free running)