

# Black rubber covered wheel

For heavy loads up to 215kg


RBN

- Industrial castor with a semi-elastic solid rubber tyre
- Material:
  - 85° Shore vulcanised black rubber tyre
  - Polypropylene rim
- Smooth central bore
- Working temperature range: - 20°C to + 60°C

## Advantages

- Soft and silent
- Absorbs shock and vibration
- Will not damage floors

Noise absorbing

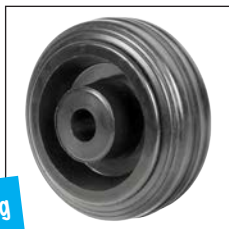

ØD



B



C



ØA

## DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØD	B	C	ØA	Maximum load (kg)	Stock*	Price each 1 to 9
RBN80-34/ML	80	34	40	12	75	✓	2,79 €
RBN100-35/ML	100	35	39	12	100	✓	3,31 €
RBN125-38/ML	125	38	45	15	125	✓	5,19 €
RBN150-40/ML	150	40	45	15	150	✓	7,36 €
RBN160-38/ML	160	38	60	20	150	-	7,67 €
RBN200-47/ML	200	47	60	20	215	-	11,04 €

Dimensions in mm

Fax **0 825 88 6000**  
Service 0,15 € / min  
+ prix appel


cial2@hpceurope.com

HPC

SUPPLEMENT 2019

273
 
## Our other products



RPP8  
RPP heavy duty timing belt, RPP8



PSG25  
Spur gear - precision range, Case hardened steel 20NCD2



AT5coured  
AT type timing belt, AT5 Steel cored polyurethane



NIN  
Self-locking nut, Steel



NT91  
Spur gear coaxial gearbox, from 10 to 35 Nm - Inline



VB  
Small 6 lobe threaded handle - female, Duroplast - Brass



SSE  
Stainless steel spherical bearing, Stainless steel / PTFE



PR821  
Idler sprocket for slat top chain, Ranges 821 and 805



GSI\_A  
Stainless steel adjustable gas spring, Stainless steel



M1  
Worm and wheel set, Machined plastic (delrin)



VPRA\_M  
Handwheel with handle, Thermosetting plastic



RPP  
Connecting plate for RPP type timing belts, RPP14

## Complementary products



RBNtc  
Swivel castor with central hole, Steel - rubber



RBNtc  
Swivel castor with central hole, Steel - rubber - with double brake



RBNpl  
Fixed castor with plate, Steel - rubber



RBNpl  
Swivel castor with plate, Steel - rubber