

# Self aligning washers




RCC  
RCX

For M6-M12 screws


- Use a pair of one concave and one convex washer
- Material: stainless steel 1.4305

## Advantages


- Spreads pressure uniformly
- Ensures screw head seats correctly

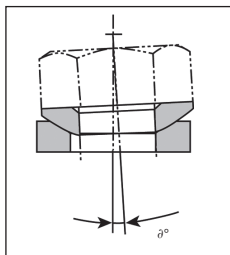

Typical application

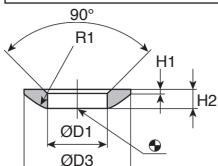

RCX convex washer

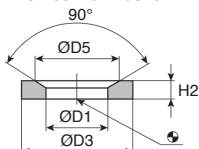

RCC concave washer



## DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	For screw	ØD1 H13	ØD3	ØD5	H1	H2	R1	Max.static load (kN)	Stock*	Price each 1 to 5
<b>Convex washer</b>										
RCX-6/SS	M6	6,4	12	-	0,7	2,3	9	9	✓	1,93 €
RCX-8/SS	M8	8,4	17	-	0,6	3,2	12	17	✓	2,63 €
RCX-10/SS	M10	10,5	21	-	0,8	4,0	15	26	✓	3,60 €
RCX-12/SS	M12	13,0	24	-	1,1	4,6	17	38	✓	4,30 €
<b>Concave washer</b>										
RCC-6/SS	M6	7,1	12	11,0	-	2,8	-	9	✓	1,96 €
RCC-8/SS	M8	9,6	17	14,5	-	3,5	-	17	✓	2,80 €
RCC-10/SS	M10	12,0	21	18,5	-	4,2	-	26	✓	3,82 €
RCC-12/SS	M12	14,2	24	20,0	-	5,0	-	38	✓	4,46 €

\*Depending on availability - Dimensions in mm

## Our other products



MSP19

Masterplate®  
glueable insert  
Ø19/Ø20, Cylindrical  
with nut



HTD8M\_30

HTD Heavy duty  
timing pulley, HTD8  
Cast



BOXKK

Boxed set of  
DIN6885A keys,  
Boxed set - Steel or  
stainless steel



HTD5M\_25

HTD Heavy duty  
timing pulley, HTD5  
Aluminium



BEAB

Knob star grip  
antibacterial, Star,  
anti-bacterial



SSDB

Stainless steel bevel  
gear, 2:1



BPMc

Stainless steel slotted  
spring plunger with  
ceramic ball tip, 303  
St...



RT70

Self-centering locking  
Assembly,  
Medium/high torque  
St...



MFBC

Flexible Bellows  
coupling, Aluminium



CLB\_M

Die cast zinc clamping  
lever - female, Zamak



BAC105

Storage bin, 8mm



PLS

Cylindrical spacer,  
Stainless steel 303

## Complementary products



RCC\_RCX

Spherical tilt washer -  
DIN6319, convex



RCX-6

Spherical tilt washer -  
DIN6319, concave



RCX-6

Spherical tilt washer -  
DIN6319, convex



WTM

Tightening washer -  
DIN6340, Steel