

Self aligning washers




**RCC
RCX**

For M6-M12 screws


- Use a pair of one concave and one convex washer
- Material: stainless steel 1.4305

Advantages


- Spreads pressure uniformly
- Ensures screw head seats correctly

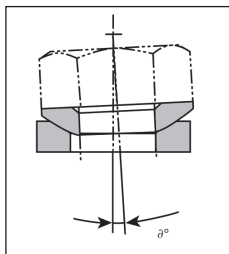

Typical application

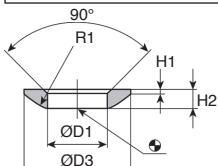

RCX convex washer

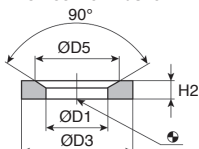

RCC concave washer



DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	For screw	ØD1 H13	ØD3	ØD5	H1	H2	R1	Max.static load (kN)	Stock*	Price each 1 to 5
Convex washer										
RCC-6/SS	M6	6,4	12	-	0,7	2,3	9	9	✓	1,93 €
RCC-8/SS	M8	8,4	17	-	0,6	3,2	12	17	✓	2,63 €
RCC-10/SS	M10	10,5	21	-	0,8	4,0	15	26	✓	3,60 €
RCC-12/SS	M12	13,0	24	-	1,1	4,6	17	38	✓	4,30 €
Concave washer										
RCC-6/SS	M6	7,1	12	11,0	-	2,8	-	9	✓	1,96 €
RCC-8/SS	M8	9,6	17	14,5	-	3,5	-	17	✓	2,80 €
RCC-10/SS	M10	12,0	21	18,5	-	4,2	-	26	✓	3,82 €
RCC-12/SS	M12	14,2	24	20,0	-	5,0	-	38	✓	4,46 €

*Depending on availability - Dimensions in mm

Our other products



EMR
Fast-locking knurled
nut, Knurled



PLA
Flat magnet, Flat
magnet with threaded
hole



MBEX
Hexagonal ended
handle, Hexagonal
ended handle



EP7
Electronic digital
position indicator, 5
numbers



HLA24
Right angle spiro
bevel gearbox, Up to
78Nm



PM2
Worm and wheel set,
Non hardened steel



BAGSS
Stainless steel
Clamping collar,
Stainless steel



CHV
Mechanical speed
variator, from 0,18 to
1,5kW



NTMbr
Set screw brass tip,
Brass-point



ABL100005
Antistatic brush,
Standard



AFSE
Locking pin with
interlocking safety



PRF_ROUL
Castor for aluminium
profile, No brake

Complementary products



RCC_RCX
Spherical tilt washer -
DIN6319, convex



RCX-6
Spherical tilt washer -
DIN6319, concave



RCX-6
Spherical tilt washer -
DIN6319, convex



WTM
Tightening washer -
DIN6340, Steel