

# Sta Rigging screw with 2 jaws **stainless steel**

Diameter from 5mm to 20mm


RDCss

## Rigging screw with 2 welded jaws

- Material : Stainless steel 316
- Supplied with fitted locking nuts

### Application

The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

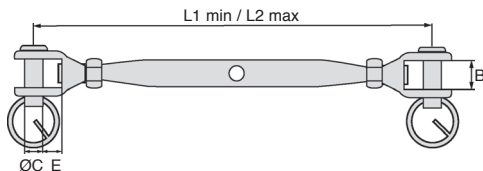

### DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-5%	-10%	On request

 
Part number	Size	Thread	ØC	B	E	L1	L2	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 2
RDC-5/SS	5	M5	5	6,5	8,0	126	190	150	0,056	✓	18,01 €
RDC-6/SS	6	M6	6	7,5	7,7	136	211	250	0,076	✓	20,04 €
RDC-8/SS	8	M8	8	11,0	9,4	170	255	360	0,154	✓	28,22 €
RDC-10/SS	10	M10	9	12,0	14,0	195	280	500	0,260	✓	36,38 €
RDC-12/SS	12	M12	12	14,0	20,0	260	380	650	0,536	✓	50,25 €
RDC-14/SS	14	M14	12	15,0	22,0	300	430	790	0,720	✓	65,54 €
RDC-16/SS	16	M16	16	21,0	24,0	315	455	980	1,086	-	94,42 €
RDC-20/SS	20	M20	20	28,0	38,0	410	560	1300	2,124	-	139,96 €

\*Depending on availability -Dimensions in mm

## Our other products



SNG  
Stainless/Polymer  
pillow block bearing,  
Cast iron - Split pillow



TBV  
Manual lifting tables,  
12kg



 
T5-10ECO  
T type timing pulley,  
Economy range - T5  
aluminium



CHB  
Worm and wheel gear  
reducer, up to 22 Nm




BOX-CSss  
Hose clamp, Box set of  
stainless steel hose  
clamps



IN1  
Internal gear,  
Machined plastic  
(delrin)



 RTE  
Rotex®, jaw coupling,  
steel



CFC  
Spring loaded position  
switch, Electric  
contact



BCM\_TP  
Modular cylindrical  
brush, Tampico  
bristles



BGC  
Oldham coupling,  
Clamp



G0  
Steel spur gear, Steel  
20NCD2



CMM\_SS  
Male rod ends DIN  
ISO12240-4, Stainless  
steel / bronze -  
Economy range

## Complementary products



RDERSS  
Stainless steel manual  
rigging screw,  
Stainless steel -  
manual