

Sta Rigging screw with 2 jaws **stainless steel**

Diameter from 5mm to 20mm


RDCss

Rigging screw with 2 welded jaws

- Material : Stainless steel 316
- Supplied with fitted locking nuts

Application

The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

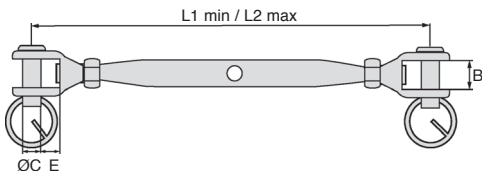

DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-5%	-10%	On request

Part number	Size	Thread	ØC	B	E	L1	L2	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 2
RDC-5/SS	5	M5	5	6,5	8,0	126	190	150	0,056	✓	18,01 €
RDC-6/SS	6	M6	6	7,5	7,7	136	211	250	0,076	✓	20,04 €
RDC-8/SS	8	M8	8	11,0	9,4	170	255	360	0,154	✓	28,22 €
RDC-10/SS	10	M10	9	12,0	14,0	195	280	500	0,260	✓	36,38 €
RDC-12/SS	12	M12	12	14,0	20,0	260	380	650	0,536	✓	50,25 €
RDC-14/SS	14	M14	12	15,0	22,0	300	430	790	0,720	✓	65,54 €
RDC-16/SS	16	M16	16	21,0	24,0	315	455	980	1,086	-	94,42 €
RDC-20/SS	20	M20	20	28,0	38,0	410	560	1300	2,124	-	139,96 €

*Depending on availability -Dimensions in mm

Our other products



CHAu

Screwed hinge, 270°



BCM_T

Driving collar, Driving collar



KB_OP

Open precision linear bearing, Precision - steel



HG5

Steel spur gear, Steel 20NCD2



BH01

Single housed bearing, Bearing fitted with adhesive



BPHT

Ball transfer unit bolt fitting, Heavy



CHM50-MOT

Asynchronous AC motorgearboxes 0.18 to 0.75kW, 0.18 to 0.75kW



GLB

Small 6 lobe female handle, Technopolymer - Stainless steel



UGH20

H Type Guide units, For Ø20 actuators



BPM

Slotted spring plunger with ball tip, Steel



PRF_BR

Clamp for aluminium profile, Clamp for profile



PCS50SS

Chain sprocket - Stainless steel, 12.7mm (DIN 08B-1)

Complementary products



RDERSS

Stainless steel manual rigging screw, Stainless steel - manual