

Sta Rigging screw with 2 jaws **stainless steel**

Diameter from 5mm to 20mm


RDCss

Rigging screw with 2 welded jaws

- Material : Stainless steel 316
- Supplied with fitted locking nuts

Application

The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

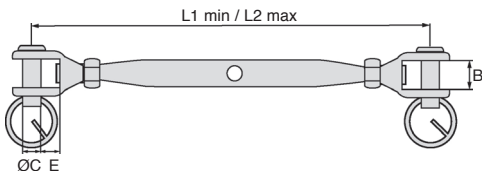

DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-5%	-10%	On request

Part number	Size	Thread	ØC	B	E	L1	L2	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 2
RDC-5/SS	5	M5	5	6,5	8,0	126	190	150	0,056	✓	18,01 €
RDC-6/SS	6	M6	6	7,5	7,7	136	211	250	0,076	✓	20,04 €
RDC-8/SS	8	M8	8	11,0	9,4	170	255	360	0,154	✓	28,22 €
RDC-10/SS	10	M10	9	12,0	14,0	195	280	500	0,260	✓	36,38 €
RDC-12/SS	12	M12	12	14,0	20,0	260	380	650	0,536	✓	50,25 €
RDC-14/SS	14	M14	12	15,0	22,0	300	430	790	0,720	✓	65,54 €
RDC-16/SS	16	M16	16	21,0	24,0	315	455	980	1,086	-	94,42 €
RDC-20/SS	20	M20	20	28,0	38,0	410	560	1300	2,124	-	139,96 €

*Depending on availability -Dimensions in mm

Our other products



NKIA

Combined bearing with inner ring, Axial load in one direction



LVT

Miniature motorised actuator 2A, 2 ampers



KITbuh

24V DC motorisation kit, Planetary gears



TBEBASE

Base plate for economic mini-table, Allows X-Y cross tables



PSG1S

Spur gear - precision range, Stainless steel 303



IN0

Internal gear, Machined plastic (delrin)



LWL

Linear ball slide - Stainless steel balls, Chariot - from 514 N to 1...



AT5M AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane



BH02

Single housed bearing assembly, Bearing



SH1

Parallel axis helical gear, Steel 20NCD2



HWL

 
Manual locking clamp, Manual locking clamp



NPCR

Adjustable cell support, Adjustable

Complementary products



RDERSS

Stainless steel manual rigging screw, Stainless steel - manual