

Sta Rigging screw with 2 jaws **stainless steel**

Diameter from 5mm to 20mm


RDCss

Rigging screw with 2 welded jaws

- Material : Stainless steel 316
- Supplied with fitted locking nuts

Application

The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

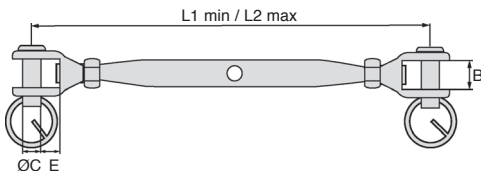

DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-5%	-10%	On request

Part number	Size	Thread	ØC	B	E	L1	L2	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 2
RDC-5/SS	5	M5	5	6,5	8,0	126	190	150	0,056	✓	18,01 €
RDC-6/SS	6	M6	6	7,5	7,7	136	211	250	0,076	✓	20,04 €
RDC-8/SS	8	M8	8	11,0	9,4	170	255	360	0,154	✓	28,22 €
RDC-10/SS	10	M10	9	12,0	14,0	195	280	500	0,260	✓	36,38 €
RDC-12/SS	12	M12	12	14,0	20,0	260	380	650	0,536	✓	50,25 €
RDC-14/SS	14	M14	12	15,0	22,0	300	430	790	0,720	✓	65,54 €
RDC-16/SS	16	M16	16	21,0	24,0	315	455	980	1,086	-	94,42 €
RDC-20/SS	20	M20	20	28,0	38,0	410	560	1300	2,124	-	139,96 €

*Depending on availability -Dimensions in mm

Our other products




DGS1

Female rod ends,
Steel / steel -
Economy range



CHAEss

 Decorative hinge,
Stainless steel



QNJ

Single row cylindrical
roller bearing, Single
flange on inner ring



CHAPAM

Weld-on hinge with
flat end, Steel



HK

Manual locking clamp,
Manual locking clamp
LRX




GLP

Small 6 lobe threaded
handle - male,
Technopolymer - Steel



GLT3E-50

 Telescopic drawer,



NANO

Speed controller 3A, 3
A



SH3

Parallel axis helical
gear, Steel 20NCD2



NCT

Square tube
connector, Fixed
angle



DB

Steel bevel gear, 2:1



PDR-RD

Mounting feet with
integrated castors,
Offset castor

Complementary products



RDERSS

Stainless steel manual
rigging screw,
Stainless steel -
manual