

Stainless steel worm and wheel gearbox

RFV63

Torque up to 140Nm

- Gearbox especially suitable for use in the food industry
- Ratios from 7.5:1 to 100:1
- B14 flange
- All surfaces smooth and polished to avoid dirt retention
- Lubricated using food quality grease
- Working temperature: -20° to +40 °C
- Material:
316 stainless steel housing

stainless steel




Accessories

- Use with a DER 4 pole motor to create a motorised gearbox
- Torque arm, mounting feet and protective covers

Info

- All information is engraved directly on to gearbox rather than being on a tag plate to avoid accumulating dirt etc

Suitable for the food industry

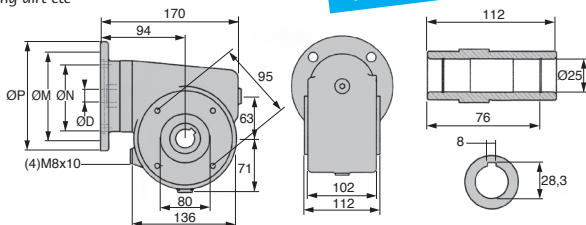

FLANGE DIMENSIONS

	$\varnothing D$	$\varnothing P$	$\varnothing M$	$\varnothing N$
71B14 flange	14	105	85	70
80B14 flange	19	120	100	80
90B14 flange	24	140	115	95

DISCOUNTS

Qty	1+	2+	4+
Disc.	List -5%	On request	

Part number	Maxi. Torque at 1400r/min (Nm)	Reduction ration	Self locking output	Prix Uni.
71B14 flange				
-	120	7,5	No	874,23 €
-	112	10	No	874,23 €
-	120	15	No	874,23 €
-	112	20	Not defined	874,23 €
-	126	25	Not defined	874,23 €
-	139	30	Yes	874,23 €
-	131	40	Yes	874,23 €
-	122	50	Yes	874,23 €
-	114	60	Yes	874,23 €
-	104	80	Yes	874,23 €
-	96	100	Yes	874,23 €

Dimensions in mm

Our other products



PRF4590_E
Angle bracket,
PRF4590



ECF
Well nut, Elastomer



GCB880
Curved guide, Ranges
880 and 881



EBC
Cap nut Hygienic
Design®, Compact



OP3_14_06
Numerical counter
accessories,
Reduction socket



PCLA_M
Clamping lever -
female, Plastic



ERC
Quick fitting cable
terminals, Eye version



IBJss
Ball and socket joint,
Stainless steel



MAC
Carabiner, Steel



EPE
Wing nuts Hygienic
Design®, Narrow



PRF_GAL
Roller for aluminium
profile, Hollow roller
ø12




GE_ET_2RS
Spherical bearing,
Hard chromium /
Teflon contact with
seals

Complementary products



 DER63
3 phase AC
asynchronous motor -
Stainless steel,
0.18kW



RFVbr
Stainless steel
gearbox - accessories,
Reaction arm



RFVfp
Stainless steel
gearbox - accessories,
Mounting bracket



RFVcap
Stainless steel
gearbox - accessories,
Open protective cover