

Stainless steel Worm and wheel motorgearbox

Create your set

For food industry

Supporting feet **RFV-FP**
(tome 2 p.326)

Protective cover closed
RFV-CAP (tome 2 p.327)

Motor 0,18kW à 1,5kW
(tome 2 p.318)

Gear reducer **RFV40, RFV50, RFV63**,
Reduction ratio of 7,5/1 to 100/1,
3 flanges to choose depending
on the motor selected

RFV-CAP protective cover
(tome 2 p.327)
open or closed to prevent
material retention in the output
bore

Reaction arm **RFV-BR**
(tome 2 p.325) to better
support the load

* See data sheet (tome 2 p.328)



Stainless steel worm and wheel gearboxes

RFVBR

Reaction arm

- Reaction arm for FRV gearbox
- Mounts on gearbox output
- Material:
316 stainless steel

Suitable for
the food industry

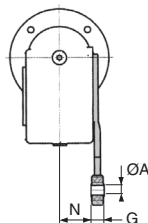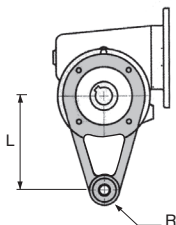

DISCOUNTS

Qty	1+	2+	4+
Disc.	List -5%	On request	

Part number	L	R	N	G	ØA	Price each
RFV40-BR/SS	100	18	31,5	14	10	43,89 €
RFV50-BR/SS	100	18	38,5	14	10	46,03 €
RFV63-BR/SS	150	18	49,0	14	10	48,17 €

Dimensions in mm

HPC

WEB
04/2021

www.hpceurope.com

Tel. +33(0)4 37 496 496