


- Flow is **adjusted by controlling the air intake**
- Materials:
Body and screws: stainless steel
Tube: acrylic

Application

- Lubricating pallet chains, bearings or other mechanical components
- Product dosing



Typical application

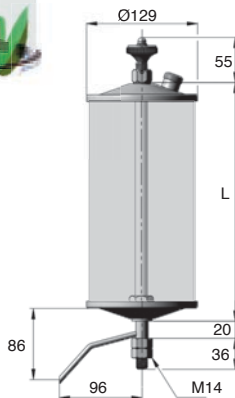

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	L	Volume (litre)	Weight (kg)	Price each 1 to 4
RGG-1.5	175	1,5	0,9	142,90 €
RGG-2.5	275	2,5	1,0	149,55 €
RGG-3.5	375	3,5	1,2	161,21 €

Dimensions in mm

Our other products



CHA1056-U4
Front hinge, 180°



DB_ECO
Bevel gear - Steel
C43, 2:1



ACLBDB
Closing system, Dual
ball catch



OP9
Numerical counter (No
of turns), 5 numbers



SR
Rack, rectangular
section, Stainless
steel



CHTRP
Single and dual
output gearboxes, Up
to 87,3Nm



BOX-WM
Washer - DIN 125,
Box set of steel
washers



MEB
Moulded plastic bevel
gear (nylon), 1:1



BDPR
Holding arm, Rigid



PSG125DL
Spur gear - precision
range, Delrin



CQA30
Adjustment slide-
system miniature, 30



BSCf
Knob for clamping,
Knurled threaded
torque

Complementary products