



RJA

PVC

- Supplied by the roll
- Can be fixed to sheet metal or thin panel
- Material: black PVC

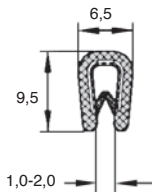

RJA00-02

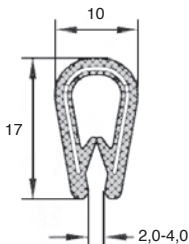

RJA00-08

DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Sold in rolls of	Stock*	Price each
RJA00-02/5	Black PVC	5 metres	✓	11,23 €
RJA00-02/100	Black PVC	100 metres	✓	180,83 €
RJA00-08/5	Black PVC	5 metres	✓	16,40 €
RJA00-08/50	Black PVC	50 metres	-	131,67 €

*Depending on availability - Dimensions in mm

Our other products



HSE-HSB

Hexagonal spacer,
Brass



MRA_SS

Stainless steel Quick
link, Stainless steel



CABma

Swaging sleeve for
fitting cable, To crimp
a wire rope



ACLALF

Adjustable foot for
aluminium profile,
Ideal for workstations



NDS20

Double cross clamp,
Parallel



RAGb

Cylindrical brush
track, For gentle
conveying and
handling



CHA1056-U4

Screwed hinge, 180°



PCH

Knob for gripping,
Mushroom



PRF19_E

Bracket for aluminium
profile, PRF19 to
PRF45



CHALss

Piano hinge, Stainless
steel



DOMI30

Domino 30 adjustable
slide, Slide DOMILINE
30 with counter and



H1

Crossed helical gear
crossed axis at 90°,
Steel 20NCD2

Complementary products



RJA00_28

Sealing strip, Clipping



RJA11_27

Sealing strip, Not
clipping