



RJA

PVC

- Supplied by the roll
- Can be fixed to sheet metal or thin panel
- Material: black PVC

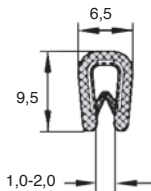

RJA00-02

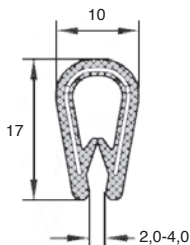

RJA00-08

DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Sold in rolls of	Stock*	Price each
RJA00-02/5	Black PVC	5 metres	✓	11,23 €
RJA00-02/100	Black PVC	100 metres	✓	180,83 €
RJA00-08/5	Black PVC	5 metres	✓	16,40 €
RJA00-08/50	Black PVC	50 metres	-	131,67 €

*Depending on availability - Dimensions in mm

Our other products



HCA

Magnetic screw with socket, Steel




T5P_T10P

Connecting plate for T type timing belts, T10



MRAeco

Low cost quick link, Steel

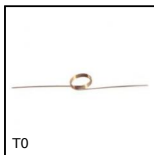

T0

Torsion spring, Stainless steel



T5M_T10M

T type timing belt per metre, T10 Steel cored polyurethane



S20

Short housing for open linear bearing, Opened - slim



PSG1HC

Skive hobbed spur gears - precision range, Case hardened steel 20NCD2



G-ECO

Eco range Spur gear, Steel C45



RTE

Rotex®, jaw coupling, Aluminium



GLB

Small 6 lobe female handle, Technopolymer -



MDB_MTB

Moulded plastic bevel gear (nylon), 3:1



RFK28C

Hypoid gearbox - Stainless steel, up to 130 Nm

Complementary products



RJA00_28

Sealing strip, Clipping



RJA11_27

Sealing strip, Not clipping