



## RJA

## PVC

- Supplied by the roll
- Can be fixed to sheet metal or thin panel
- Material: black PVC

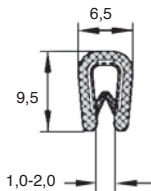

RJA00-02

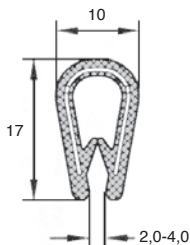

RJA00-08

### DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

### DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Sold in rolls of	Stock*	Price each
RJA00-02/5	Black PVC	5 metres	✓	11,23 €
RJA00-02/100	Black PVC	100 metres	✓	180,83 €
RJA00-08/5	Black PVC	5 metres	✓	16,40 €
RJA00-08/50	Black PVC	50 metres	-	131,67 €

\*Depending on availability - Dimensions in mm

## Our other products



METEB

Self-lubricating blanks, Bronze BP25



FRtool

Tool for thread repair inserts, Assembly tool



PCF4

Conical flexible mount, Square base plate



CHMR30

Worm and wheel gear reducer, up to 28 Nm



PLB

Cylindrical spacer, Brass



ACLEPP

Right angled bracket for aluminium profile, 2 holes




PSG2

Spur gear - precision range, Pre-hardened Steel 35NCD6



CHTRB

 Single and dual output gearboxes, Up to 53,1 Nm



PM3

Worm and wheel set, Machined plastic



RTTss

Locking assembly, Medium/high torque



NPCR

Adjustable cell support, Adjustable



MDB\_MTB

Moulded plastic bevel gear (nylon), 3:1

## Complementary products



RJA00\_28

Sealing strip, Clipping



RJA11\_27

Sealing strip, Not clipping