



RJA

PVC

- Supplied by the roll
- Can be fixed to sheet metal or thin panel
- Material: black PVC

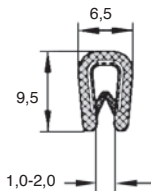

RJA00-02

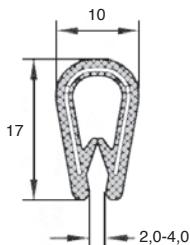

RJA00-08

DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Sold in rolls of	Stock*	Price each
RJA00-02/5	Black PVC	5 metres	✓	11,23 €
RJA00-02/100	Black PVC	100 metres	✓	180,83 €
RJA00-08/5	Black PVC	5 metres	✓	16,40 €
RJA00-08/50	Black PVC	50 metres	-	131,67 €

*Depending on availability - Dimensions in mm

Our other products




RAGFLOW

Floway2® roller track,
Roller track



EBC

Cap nut Hygienic
Design®, Compact

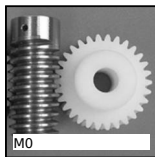

M0

Worm and wheel set,
Machined plastic
(delrin)



BG

Oldham coupling,
With set screw



BFD

Locking pin for bush,
+180°C



H2

Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



ZBconique

Machined plastic
bevel gear, 1:1




EMS

Stainless steel knurled
thumb nut, Knurled



CHA138

 Screwed hinge with
threaded insert, 138



TBV

Manual lifting tables,
12kg



Q1

Self-aligning radial
ball bearing, Steel



AT10-BAR

AT type tooth bar
stock, AT10

Complementary products



RJA00_28

Sealing strip, Clipping



RJA11_27

Sealing strip, Not
clipping