



## RJA

## PVC

- Supplied by the roll
- Can be fixed to sheet metal or thin panel
- Material: black PVC

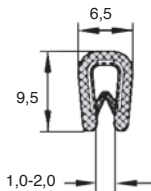

RJA00-02

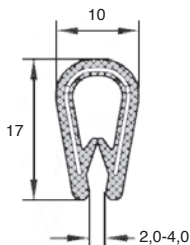

RJA00-08

### DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

### DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Sold in rolls of	Stock*	Price each
RJA00-02/5	Black PVC	5 metres	✓	11,23 €
RJA00-02/100	Black PVC	100 metres	✓	180,83 €
RJA00-08/5	Black PVC	5 metres	✓	16,40 €
RJA00-08/50	Black PVC	50 metres	-	131,67 €

\*Depending on availability - Dimensions in mm

## Our other products



NT62  
Spur gear coaxial gearbox, from 6 to 18 Nm - In-line



GE\_ET\_2RS  
Spherical bushing, Hard chromium / Teflon contact with seals



ESCON  
Speed controller 5A accessories, USB cable for PC link




TCLar  
Automatic chain tensioner, With wide guide



CHAsb89  
Hinge without pin, Plastic hinge



 BIM  
Indexing plunger mini, miniature



PF40  
Worm and wheel gear reducer, up to 18 Nm



T5P\_T10P  
Connecting plate for T type timing belts, T10



RT25  
Self-centering flanged locking assembly, Medium/high torque



PR40  
Articulated foot Ø50, Ø 50



GAL22  
Conveyor wheel, Zinc plated steel



BCTH  
Mushroom headed button Hygienic Usit®, With female thread and high ...

## Complementary products



RJA00\_28  
Sealing strip, Clipping



RJA11\_27  
Sealing strip, Not clipping