

Linear sealing strip




RJA

PVC / EPDM


- Linear sealing strip supplied by the roll
- Can be clipped to sheet metal or thin panels

Characteristics of EPDM


- Hardness 30 to 90 Shore A
- Working temperature: -35°C to +120°C
- Very good resistance to ozone, acid, hot water, and ageing
- Almost impermeable to gas
- Good alkaline resistance
- Not resistant to oils or diesel
- Flammable

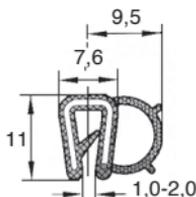


RJA00-28

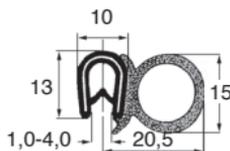

RJA10-11

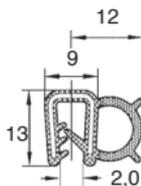

RJAA0-02

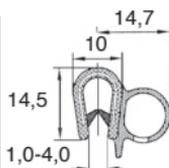

RJAA0-01

DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request


Part number	Material	Supplied in rolls of	Stock*	Price each
RJA00-28/5	Black EPDM	5 metres	✓	44,50 €
RJA00-28/50	Black EPDM	50 metres	-	356,82 €
RJA10-11/5	Black PVC / EPDM	5 metres	✓	54,97 €
RJAA0-01/5	Black PVC / EPDM	5 metres	✓	71,86 €
RJAA0-01/50	Black PVC / EPDM	50 metres	-	570,56 €
RJAA0-02/5	Black EPDM	5 metres	✓	61,71 €
RJAA0-02/50	Black EPDM	50 metres	-	489,45 €

*Depending on availability - Dimensions in mm


- Linear sealing strip supplied by the roll
- Can be clipped to sheet metal or thin panels

Characteristics of EPDM


- Hardness 30 to 90 Shore A
- Working temperature: -35°C to +120°C
- Very good resistance to ozone, acid, hot water, and ageing
- Almost impermeable to gas
- Good alkaline resistance
- Not resistant to oils or diesel
- Flammable

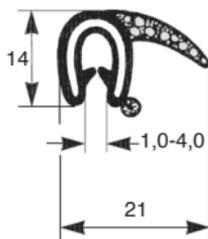

RJA10-03

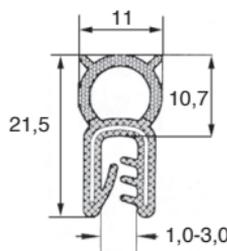

RJA10-10

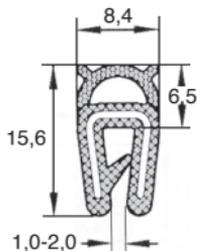

RJA00-25

DISCOUNTS for 5m DISCOUNTS for 25m & 50m

Qty	1+	5+	50+	Qty	1+	3+	6+
Disc.	List	-10%	Request	Disc.	List	-10%	On request

Part number	Material	Supplied in rolls of	Stock*	Price each
RJA10-03/5	Black EPDM	5 metres	✓	51,98 €
RJA10-03/50	Black EPDM	50 metres	-	136,89 €
RJA10-10/5	Black EPDM	5 metres	✓	57,36 €
RJA10-10/25	Black EPDM	25 metres	✓	210,22 €
RJA00-25/5	Black EPDM	5 metres	✓	51,98 €
RJA00-25/50	Black EPDM	50 metres	✓	416,51 €

*Depending on availability - Dimensions in mm


Linear sealing strip

Stock


RJA

PVC

- Linear sealing strip supplied by the roll
- Can be fixed to sheet metal or thin panel
- Material: black PVC

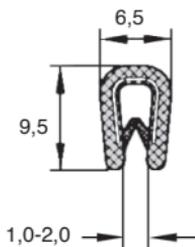

RJA00-02

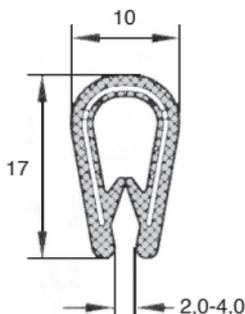

RJA00-08

DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request


Part number	Material	Sold in rolls of	Stock*	Price each
RJA00-02/5	Black PVC	5 metres	✓	18,08 €
RJA00-02/100	Black PVC	100 metres	✓	291,57 €
RJA00-08/5	Black PVC	5 metres	✓	28,66 €
RJA00-08/50	Black PVC	50 metres	✓	230,39 €

*Depending on availability - Dimensions in mm


- Linear sealing strip supplied by the roll

Characteristics of EPDM

- Hardness 30 to 90 Shore A
- Working temperature: -35°C to +120°C
- Very good resistance to ozone, acid, hot water, and ageing
- Almost impermeable to gas
- Good alkaline resistance
- Not resistant to oils or diesel
- Flammable

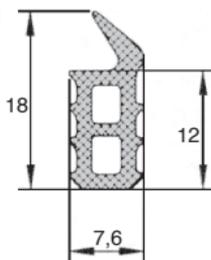

RJA11-27

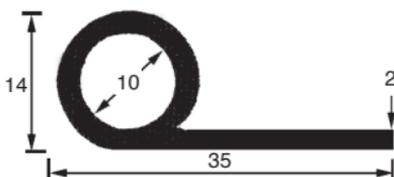

RJA90-38

DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Sold in rolls of	Stock*	Price each
RJA11-27/5	Black EPDM	5 metres	✓	36,39 €
RJA11-27/100	Black EPDM	100 metres	-	563,16 €
RJA90-38/5	Black EPDM	5 metres	✓	48,13 €
RJA90-38/50	Black EPDM	50 metres	-	385,80 €

*Depending on availability - Dimensions in mm