



- Supplied by the roll
- Can be fixed to sheet metal or thin panels

Characteristics of EPDM


- Hardness 30 to 90 Shore A
- Working temperature: -35°C to +120°C
- Very good ozone, acid, hot water, and ageing resistance
- Almost impermeable to gas
- Good alkaline resistance
- No resistant to oils or some other hydrocarbons
- Flammable

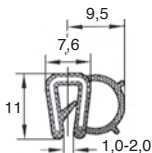

 
RJA00-28



RJA10-11

 

RJAA0-02

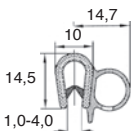

RJAA0-01

DISCOUNTS for 5m

Qty.	1+	5+	50+
Disc.	List	-10%	On request

DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request


DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Supplied in rolls of	Stock*	Price each
RJA00-28/5	Black EPDM	5 metres	✓	29,43 €
RJA00-28/100	Black EPDM	100 metres	-	471,82 €
RJA10-11/5	Black PVC / EPDM	5 metres	✓	38,26 €
RJA10-11/100	Black PVC / EPDM	100 metres	-	611,92 €
RJAA0-01/5	Black PVC / EPDM	5 metres	✓	46,37 €
RJAA0-01/50	Black PVC / EPDM	50 metres	-	371,06 €
RJAA0-02/5	Black EPDM	5 metres	✓	39,51 €
RJAA0-02/50	Black EPDM	50 metres	-	315,76 €

*Depending on availability - Dimensions in mm

 Our other products



RDE-W

Sealing washer
Hygienic Usit®,
Stainless steel - White
EPDM



CHMR90

Worm and wheel gear
reducer, up to 540
Nm




PO

Pull handle - Multi-
sector, Tapped
recessed insert



CHA35

 Hinge for aluminium
profile, Hinge



RPP14

RPP heavy duty
timing belt, RPP14



CHAR6035

Spring hinge,
screwed/welded



CLQassortiment

Assorted feeler strips,
Assorted feeler strips



SLVHlok

Vertical toggle clamp,
Vertical toggle clamp /
horizontal foot



DIV

Locking bolt, With grip
- Steel



ACLBMC

Detector support for
aluminium profile,
Sensor holder



RBNpl

Swivel castor with
plate, Steel - rubber



EHD08-3

Internal epicyclic
servo reducers, from
20 to 50 Nm

Complementary products



RJA10_03

Sealing strip, Clipping



RJA11_27

Sealing strip, Not
clipping