



- Supplied by the roll
- Can be fixed to sheet metal or thin panels

### Characteristics of EPDM


- Hardness 30 to 90 Shore A
- Working temperature: -35°C to +120°C
- Very good ozone, acid, hot water, and ageing resistance
- Almost impermeable to gas
- Good alkaline resistance
- No resistant to oils or some other hydrocarbons
- Flammable

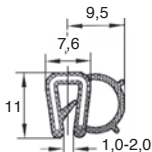

 
RJA00-28



RJA10-11

 

RJAA0-02

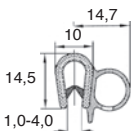

RJAA0-01

### DISCOUNTS for 5m

Qty.	1+	5+	50+
Disc.	List	-10%	On request

### DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

### DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Supplied in rolls of	Stock*	Price each
RJA00-28/5	Black EPDM	5 metres	✓	29,43 €
RJA00-28/100	Black EPDM	100 metres	-	471,82 €
RJA10-11/5	Black PVC / EPDM	5 metres	✓	38,26 €
RJA10-11/100	Black PVC / EPDM	100 metres	-	611,92 €
RJAA0-01/5	Black PVC / EPDM	5 metres	✓	46,37 €
RJAA0-01/50	Black PVC / EPDM	50 metres	-	371,06 €
RJAA0-02/5	Black EPDM	5 metres	✓	39,51 €
RJAA0-02/50	Black EPDM	50 metres	-	315,76 €

 
\*Depending on availability - Dimensions in mm

## Our other products



CLR

Straight clevis,  
Straight clevis for use  
with a male clevis



MBrondelle

Stop washer, Stop  
washer MB



UTKswr

Utilitak® V rail, V rail



SERB

Universal latch key,  
Universal latch key



GAL 42

Guide roller for plate  
chain return, Without  
ball bearing



PNA

PERIFLEX® elastic  
coupling, Complete  
coupling



PP35

Worm and wheel gear  
reducer, from 2.20 to  
4.10 Nm



BLHM20

Right angled gearbox,  
double output shafts,  
up to 1.77 Nm



AT10-25ECO

AT type timing pulley,  
Economy range -  
AT10 aluminium



KBS\_UU

Stainless steel closed  
precision linear  
bearing, Precision -



GSA\_A

Adjustable gas spring,  
Steel



PCS62K

Chain sprocket with  
hardened teeth,  
15.875mm (DIN10B-1)

## Complementary products



RJA10\_03

Sealing strip, Clipping



RJA11\_27

Sealing strip, Not  
clipping