



- Supplied by the roll
- Can be fixed to sheet metal or thin panels

### Characteristics of EPDM


- Hardness 30 to 90 Shore A
- Working temperature: -35°C to +120°C
- Very good ozone, acid, hot water, and ageing resistance
- Almost impermeable to gas
- Good alkaline resistance
- No resistant to oils or some other hydrocarbons
- Flammable

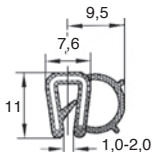

 
RJA00-28



RJA10-11

 

RJAA0-02

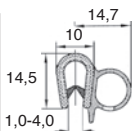

RJAA0-01

### DISCOUNTS for 5m

Qty.	1+	5+	50+
Disc.	List	-10%	On request

### DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

### DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

 
Part number	Material	Supplied in rolls of	Stock*	Price each
RJA00-28/5	Black EPDM	5 metres	✓	29,43 €
RJA00-28/100	Black EPDM	100 metres	-	471,82 €
RJA10-11/5	Black PVC / EPDM	5 metres	✓	38,26 €
RJA10-11/100	Black PVC / EPDM	100 metres	-	611,92 €
RJAA0-01/5	Black PVC / EPDM	5 metres	✓	46,37 €
RJAA0-01/50	Black PVC / EPDM	50 metres	-	371,06 €
RJAA0-02/5	Black EPDM	5 metres	✓	39,51 €
RJAA0-02/50	Black EPDM	50 metres	-	315,76 €

\*Depending on availability - Dimensions in mm

## Our other products



Worm and wheel gear reducer, up to 980 Nm



Single row cylindrical roller bearing, 1 fixed inner flange and 1 fr...



Stainless steel garnet hinge, To be welded



Joining plate for aluminium profile, Right angled connection



Connecting plate for AT type timing belts, AT10



Shaft for linear guides, Hardened ground steel



Handwheel with handle, Polyamide



Slotted spring plunger with ball tip, Stainless steel 303



Lock for latch clamp, Strike plate



Rigging screw (hook/hook), Steel



90° ball and socket joints DIN71802, Stainless steel



Stainless steel protective cover, Open protective cover

## Complementary products



Sealing strip, Clipping



Sealing strip, Not clipping