



- Supplied by the roll
- Can be fixed to sheet metal or thin panels

Characteristics of EPDM


- Hardness 30 to 90 Shore A
- Working temperature: -35°C to +120°C
- Very good ozone, acid, hot water, and ageing resistance
- Almost impermeable to gas
- Good alkaline resistance
- No resistant to oils or some other hydrocarbons
- Flammable

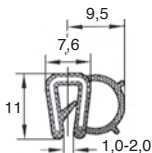

 
RJA00-28



RJA10-11

 

RJAA0-02

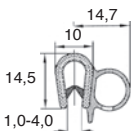

RJAA0-01

DISCOUNTS for 5m

Qty.	1+	5+	50+
Disc.	List	-10%	On request

DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Supplied in rolls of	Stock*	Price each
RJA00-28/5	Black EPDM	5 metres	✓	29,43 €
RJA00-28/100	Black EPDM	100 metres	-	471,82 €
RJA10-11/5	Black PVC / EPDM	5 metres	✓	38,26 €
RJA10-11/100	Black PVC / EPDM	100 metres	-	611,92 €
RJAA0-01/5	Black PVC / EPDM	5 metres	✓	46,37 €
RJAA0-01/50	Black PVC / EPDM	50 metres	-	371,06 €
RJAA0-02/5	Black EPDM	5 metres	✓	39,51 €
RJAA0-02/50	Black EPDM	50 metres	-	315,76 €

*Depending on availability - Dimensions in mm

Our other products



PRF_BP

Doorstop for aluminium profile, Swing door stop



CHB

Worm and wheel gear reducer, up to 41 Nm



KK

Rounded end feather key, Steel



BLHB40_

Right angled gearbox, bored shafts, up to 10.3 Nm



CHAC4040NP

Square hinge with riveted pin, not drilled, Square with riveted pin,...



NT122

Spur gear coaxial gearbox, from 32 to 85 Nm - Inline



AC

Strike for toggle latch, 15mm



PRF_ROUL_F_

Castor for aluminium profile, With brake



ZG0

Plastic spur gear, Machined plastic



RLXAC8

Free roller, Steel



UGPC

Actuator guide kit, Short bearing



BABTV

Ball lock pins lockable, Stainless steel

Complementary products



RJA10_03

Sealing strip, Clipping



RJA11_27

Sealing strip, Not clipping