



RJA

PVC

- Supplied by the roll
- Can be fixed to sheet metal or thin panel
- Material: black PVC

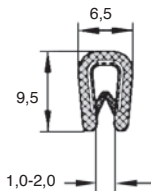

RJA00-02

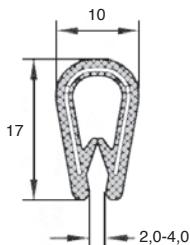

RJA00-08

DISCOUNTS for 5m

Qty	1+	5+	50+
Disc.	List	-10%	On request

DISCOUNTS for 50-100m

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Sold in rolls of	Stock*	Price each
RJA00-02/5	Black PVC	5 metres	✓	11,23 €
RJA00-02/100	Black PVC	100 metres	✓	180,83 €
RJA00-08/5	Black PVC	5 metres	✓	16,40 €
RJA00-08/50	Black PVC	50 metres	-	131,67 €

*Depending on availability - Dimensions in mm

Our other products



M1

Worm and wheel set,
Hardened steel



M1

Worm and wheel set,
Machined plastic
(delrin)



CLG3

Moulded plastic spur
gear, Moulded plastic
(nylon)



BAC105

Storage bin, 8mm



HTD14M_55

HTD Heavy duty
timing pulley, HTD14
Cast



COA-COG

Surface mounting
plate, Surface
mounting plate for
clevis



AT5P_AT10P

Connecting plate for
AT type timing belts,
AT10



WTM

Tightening washer -
DIN6340, Steel



RBGtc

Swivel castor with
central hole, Steel -



T5-BAR

T type tooth bar
stock, T5



UCP_SS

Stainless steel pillow
block bearing,



TOC

Short swivel head,
Short

Complementary products



RJA00_28

Sealing strip, Clipping



RJA11_27

Sealing strip, Not
clipping