



- Supplied by the roll
- Can be fixed to sheet metal or thin panels

Characteristics of EPDM


- Hardness 30 to 90 Shore A
- Working temperature: -35°C to +120°C
- Very good ozone, acid, hot water, and ageing resistance
- Almost impermeable to gas
- Good alkaline resistance
- No resistant to oils or some other hydrocarbons
- Flammable

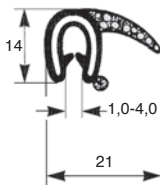

RJA10-03

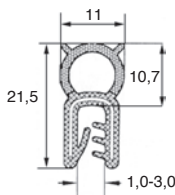

RJA10-10

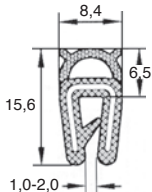

RJA00-25

DISCOUNTS for 5m DISCOUNTS for 25m & 50m

Qty	1+	5+	50+	Qty	1+	3+	6+
Disc.	List	-10%	Request	Disc.	List	-10%	On request

Part number	Material	Supplied in rolls of	Stock*	Price each
RJA10-03/5	Black EPDM	5 metres	✓	36,81 €
RJA10-03/50	Black EPDM	50 metres	-	147,39 €
RJA10-10/5	Black EPDM	5 metres	✓	38,26 €
RJA10-10/25	Black EPDM	25 metres	✓	152,89 €
RJA00-25/5	Black EPDM	5 metres	✓	36,81 €
RJA00-25/50	Black EPDM	50 metres	✓	294,87 €

*Depending on availability - Dimensions in mm

Our other products



CQA20
Accessory for adjustment slide-system, 20



CLB_M
Die cast zinc clamping lever - female, Zamak



T10_21_AL
T type timing pulley, Economy range - T10 aluminium



CHML50
Worm and wheel gear reducer, up to 107 Nm - Integrated torque limiter



PRF4545
Standard aluminium profile, 45 x 45 mm



ECF
Well nut, Chloroprene elastomer



ADSR
Backlash free coupling Gerwah®, from 12.5 to 525Nm



PCS6ECO
Chain sprocket - steel, 6mm (DIN 04-1)



TCSH
Automatic chain tensioner, With support



PRF_FIX_ANG
Fastener for aluminium profile, Angular joint



TM_CTM_CTF
Suction cup threaded insert, Insert for suction cup - Tread



OP7
Mechanical digital position indicator, 5 numbers

Complementary products



RJA00_28
Sealing strip, Clipping



RJA11_27
Sealing strip, Not clipping