



- Supplied by the roll
- Can be fixed to sheet metal or thin panels

Characteristics of EPDM


- Hardness 30 to 90 Shore A
- Working temperature: -35°C to +120°C
- Very good ozone, acid, hot water, and ageing resistance
- Almost impermeable to gas
- Good alkaline resistance
- No resistant to oils or some other hydrocarbons
- Flammable

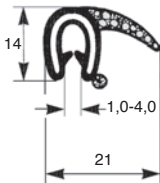

RJA10-03

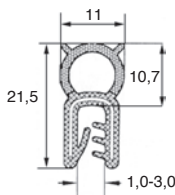

RJA10-10

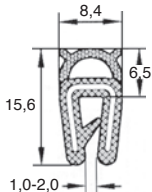

RJA00-25

DISCOUNTS for 5m DISCOUNTS for 25m & 50m

Qty	1+	5+	50+	Qty	1+	3+	6+
Disc.	List	-10%	Request	Disc.	List	-10%	On request

Part number	Material	Supplied in rolls of	Stock*	Price each
RJA10-03/5	Black EPDM	5 metres	✓	36,81 €
RJA10-03/50	Black EPDM	50 metres	-	147,39 €
RJA10-10/5	Black EPDM	5 metres	✓	38,26 €
RJA10-10/25	Black EPDM	25 metres	✓	152,89 €
RJA00-25/5	Black EPDM	5 metres	✓	36,81 €
RJA00-25/50	Black EPDM	50 metres	✓	294,87 €

*Depending on availability - Dimensions in mm

Our other products



VTLF
3 lobed handle,
Polyamide - Brass



D19 D29
Compression springs
in metre length
stainless steel, by the
metre



PAMF80EB
Articulated foot with
sheet metal base
Ø80, Articulated foot



CAP882
Flexible slat top chain
acetal, Large range
882



MHQMEP
Arm with rotating
handle, Square bore



GAL 42
Guide roller for plate
chain return, Without
ball bearing



SVR15
Screwjack with
travelling nut, with
moving nut



PO
Pull handle - Multi-
sector, Tapped
recessed insert




PCLA_T
Technopolymer
clamping lever - male,



CHAFR
Adjustable friction
hinges, Friction



BLHT20
Right angled gearbox,
from 0.66 to 1.77 Nm

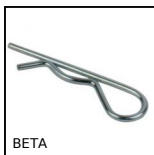

BETA
Hitch pin, Hitch

Complementary products



RJA00_28
Sealing strip, Clipping



RJA11_27
Sealing strip, Not
clipping